

## Front adapters - FLKM S135-454-4UA/S400 - 2314859

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



The FLKM S135/S400 adapter connects a SIMATIC® S5 plug directly to the SIMATIC® S7 400 base board.  
Conversion: 6ES5 454-4UA14 to 6ES7 422 1BH11-0AA0

RoHS

### Key Commercial Data

|              |                                                                                                         |
|--------------|---------------------------------------------------------------------------------------------------------|
| Packing unit | 1 pc                                                                                                    |
| GTIN         | <br>4 046356 155311 |
| GTIN         | 4046356155311                                                                                           |

### Technical data

#### Note

|              |                                           |
|--------------|-------------------------------------------|
| Type of note | Notes on operation                        |
| Note         | The LEDs of the S7-400 module are hidden. |

#### Ambient conditions

|                                         |                  |
|-----------------------------------------|------------------|
| Ambient temperature (operation)         | -20 °C ... 50 °C |
| Ambient temperature (storage/transport) | -20 °C ... 70 °C |
| Degree of protection                    | IP00             |

#### General

|                                    |                                                        |
|------------------------------------|--------------------------------------------------------|
| Max. permissible operating voltage | 60 V DC                                                |
| Max. permissible current           | 4 A (per path)                                         |
|                                    | 4 A (per connection, supply via separate power supply) |
| Mounting position                  | any                                                    |

#### Connection data

|                   |                            |
|-------------------|----------------------------|
| Connection name   | Field level                |
| Connection method | SIEMENS S5-135 U pin strip |

#### Supported controller

|            |                  |
|------------|------------------|
| Controller | SIEMENS S5-135 U |
|------------|------------------|

## Front adapters - FLKM S135-454-4UA/S400 - 2314859

### Technical data

#### Supported controller


|                     |                |
|---------------------|----------------|
| - suitable I/O card | 6ES5 454-4UA14 |
|---------------------|----------------|

#### Environmental Product Compliance

|            |                                                                                                     |
|------------|-----------------------------------------------------------------------------------------------------|
| China RoHS | Environmentally Friendly Use Period = 50 years                                                      |
|            | For details about hazardous substances go to tab "Downloads", Category "Manufacturer's declaration" |

### Drawings

Circuit diagram

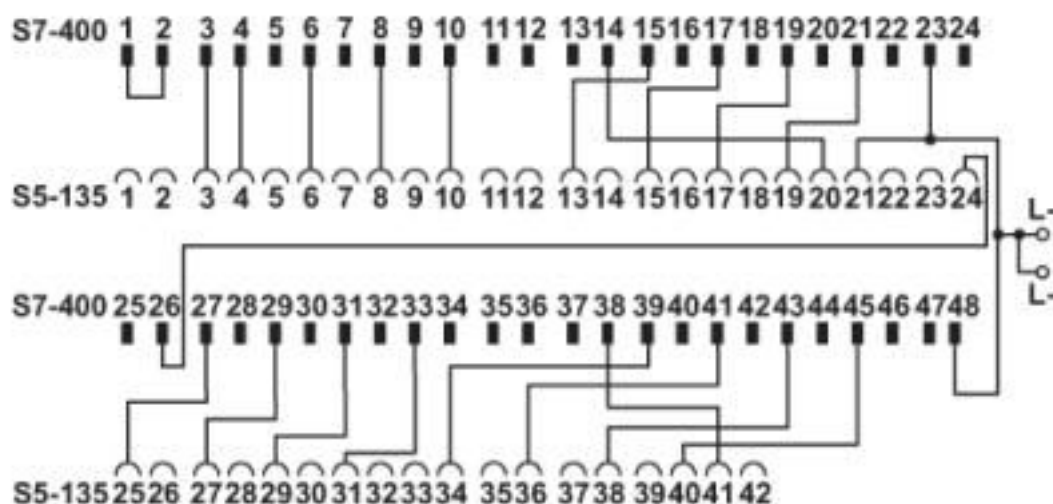

FLKM S135-454-4UA/S400 connection scheme

### Classifications

#### eCl@ss

|            |          |
|------------|----------|
| eCl@ss 4.0 | 27250300 |
| eCl@ss 4.1 | 27250300 |
| eCl@ss 5.0 | 27250300 |
| eCl@ss 5.1 | 27250300 |
| eCl@ss 6.0 | 27249200 |
| eCl@ss 7.0 | 27249290 |
| eCl@ss 8.0 | 27249290 |
| eCl@ss 9.0 | 27242292 |

#### ETIM

|          |          |
|----------|----------|
| ETIM 4.0 | EC002584 |
| ETIM 5.0 | EC002584 |
| ETIM 6.0 | EC002584 |

## Front adapters - FLKM S135-454-4UA/S400 - 2314859

### Classifications

#### ETIM

|          |          |
|----------|----------|
| ETIM 7.0 | EC002584 |
|----------|----------|

#### UNSPSC

|               |          |
|---------------|----------|
| UNSPSC 6.01   | 30211824 |
| UNSPSC 7.0901 | 39121421 |
| UNSPSC 11     | 39121421 |
| UNSPSC 12.01  | 39121421 |
| UNSPSC 13.2   | 32151601 |
| UNSPSC 19.0   | 32151601 |

### Approvals

#### Approvals

#### Approvals

#### EAC

#### Ex Approvals

#### Approval details

|     |                                                                                     |                          |
|-----|-------------------------------------------------------------------------------------|--------------------------|
| EAC |  | RU C-<br>DE.A*30.B.01742 |
|-----|-------------------------------------------------------------------------------------|--------------------------|

Phoenix Contact 2020 © - all rights reserved  
<http://www.phoenixcontact.com>

PHOENIX CONTACT GmbH & Co. KG  
Flachsmarktstr. 8  
32825 Blomberg  
Germany  
Tel. +49 5235 300  
Fax +49 5235 3 41200  
<http://www.phoenixcontact.com>

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Phoenix Contact:

2314859