

## Front adapters - FLKM-PA-2D15/HW/DO/C300 - 2900924

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



VARIOFACE front adapter, for Honeywell C300, Series C I/O. Specifically for connecting PLC-V8/D15.../OUT. Transmission of 2 x 8 channels.

### Your advantages

- Front adapter with two 15-pos. D-SUB connectors
- Specifically for connecting PLC-V8/D15.../OUT
- Pre-assembled system cables are connected directly to I/O modules using the front adapters

### Key Commercial Data

Packing unit	1 pc
GTIN	
GTIN	4046356551182

### Technical data

#### Ambient conditions

Ambient temperature (operation)	-20 °C ... 70 °C
Ambient temperature (storage/transport)	-20 °C ... 70 °C
Maximum altitude	≤ 2000 m
Degree of protection	IP00
	≤ IP54 (Installation location)

#### General

Max. permissible operating voltage	60 V DC
Max. permissible current	1 A (per path)
Mounting position	any
Assembly instructions	In rows with zero spacing

#### Standards and Regulations

Standards/regulations	DIN EN 50178
-----------------------	--------------

# Front adapters - FLKM-PA-2D15/HW/DO/C300 - 2900924

## Technical data

### Standards and Regulations

	IEC 60664
Rated insulation voltage	63 V
Rated surge voltage	0.6 kV (Functional insulation)
Pollution degree	2
Overvoltage category	II

### Connection data

Connection name	Field level
Connection method	D-SUB pin strip
Number of connections	2
Number of positions	15

### Supported controller


Controller	HONEYWELL Experion PKS C300/C-Series
- suitable I/O card	TDOB01 (non-redundant)
	TDOB11 (redundant)

### Environmental Product Compliance

China RoHS	Environmentally Friendly Use Period = 50 years
	For details about hazardous substances go to tab "Downloads", Category "Manufacturer's declaration"

## Drawings

Circuit diagram

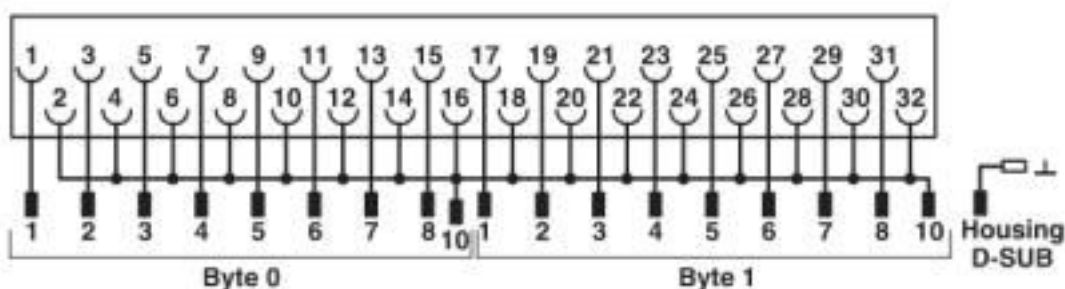

Connection scheme: FLKM-PA-2D15/HW/DO/C300

## Classifications

eCl@ss

eCl@ss 10.0.1	27242292
eCl@ss 4.0	27250300
eCl@ss 4.1	27250300
eCl@ss 5.0	27250300

# Front adapters - FLKM-PA-2D15/HW/DO/C300 - 2900924

## Classifications

### eCl@ss

eCl@ss 5.1	27250300
eCl@ss 6.0	27249200
eCl@ss 7.0	27249290
eCl@ss 8.0	27249290
eCl@ss 9.0	27242292

### ETIM

ETIM 4.0	EC002584
ETIM 5.0	EC002584
ETIM 6.0	EC002584
ETIM 7.0	EC002584

### UNSPSC

UNSPSC 6.01	30211824
UNSPSC 7.0901	39121421
UNSPSC 11	39121421
UNSPSC 12.01	39121421
UNSPSC 13.2	32151601
UNSPSC 18.0	32151601
UNSPSC 19.0	32151601
UNSPSC 20.0	32151601
UNSPSC 21.0	32151601

## Approvals

### Approvals

---

Approvals

EAC

---

Ex Approvals

### Approval details

EAC		RU C- DE.A*30.B.01742
-----	---	--------------------------

Phoenix Contact 2020 © - all rights reserved  
<http://www.phoenixcontact.com>

PHOENIX CONTACT GmbH & Co. KG  
Flachmarktstr. 8  
32825 Blomberg  
Germany  
Tel. +49 5235 300  
Fax +49 5235 3 41200  
<http://www.phoenixcontact.com>

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Phoenix Contact:](#)

[2900924](#)