

## Housing - HC-B 24-TFQ-H/O2STM40G - 1412450


Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



HEAVYCON B24 sleeve housing, for double locking latch, height: 76 mm, with 2 x M40 thread, straight cable outlet

RoHS

### Key Commercial Data

Packing unit	1 pc
GTIN	 4 046356 962742
GTIN	4046356962742

### Technical data

#### General

Note	For contact inserts HC-B24, BB46, BBB64, D64, DD108, M
Size	B24

#### Ambient conditions

Ambient temperature (operation)	-40 °C ... 125 °C
Degree of protection	IP65

#### Material data

Housing material	Aluminum die-cast
------------------	-------------------


#### Environmental Product Compliance

China RoHS	Environmentally friendly use period: unlimited = EFUP-e
	No hazardous substances above threshold values

### Drawings

## Housing - HC-B 24-TFQ-H/O2STM40G - 1412450

Dimensional drawing

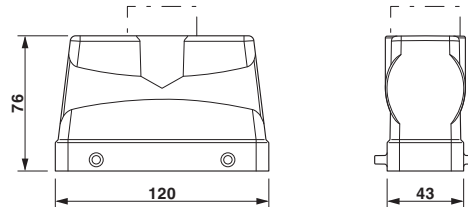

Dimensional drawing

### Approvals

#### Approvals

---

#### Approvals


EAC

---

#### Ex Approvals

---

#### Approval details

EAC		RU C- DE.AI30.B.01102
-----	---	--------------------------

Phoenix Contact 2018 © - all rights reserved  
<http://www.phoenixcontact.com>

PHOENIX CONTACT GmbH & Co. KG  
Flachsmarktstr. 8  
32825 Blomberg  
Germany  
Tel. +49 5235 300  
Fax +49 5235 3 41200  
<http://www.phoenixcontact.com>

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Phoenix Contact:

1412450