

## Panel mounting base - RC-00000005200 - 1592599

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid  
(<http://phoenixcontact.com/download>)



Panel mounting base, straight, Screw locking, M23, Radial O-ring, 4x Ø2,7, shielded: yes, panel thickness min.: 2.7 mm, panel thickness max.: 3.5 mm

**RoHS**

### Key Commercial Data

Packing unit	40 pc
GTIN	 4 046356 191753
GTIN	4046356191753

### Technical data

#### General

Type of locking	Screw locking
Pg housing screw connection	none
Mounting type	4x Ø2,7

#### Ambient conditions

Ambient temperature	-20 °C ... 125 °C
Degree of protection	IP67

#### Material

Housing material	Turned parts: copper zinc alloy (CuZn), die-cast parts: zinc (GD-Zn)
Gasket and O-ring material	FPM

#### Specifications according to DIN EN 61984:2001

Installation height max.	2000 m
--------------------------	--------

#### Environmental Product Compliance

REACH SVHC	Lead 7439-92-1
China RoHS	Environmentally Friendly Use Period = 50

## Panel mounting base - RC-00000005200 - 1592599


### Technical data

#### Environmental Product Compliance

For details about hazardous substances go to tab "Downloads",  
Category "Manufacturer's declaration"

### Drawings

Dimensional drawing

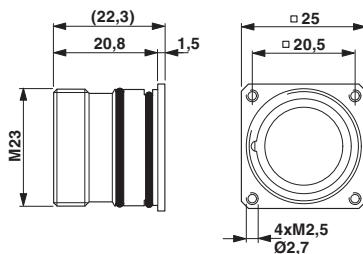

Phoenix Contact 2018 © - all rights reserved  
<http://www.phoenixcontact.com>

PHOENIX CONTACT GmbH & Co. KG  
Flachsmarktstr. 8  
32825 Blomberg  
Germany  
Tel. +49 5235 300  
Fax +49 5235 3 41200  
<http://www.phoenixcontact.com>

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Phoenix Contact:](#)

[1592599](#)