

Rear panel feed-through - RC-0000000Q0FZ - 1592924

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Rear panel feed-through, straight, Axial O-ring, Central fixing, shielded: yes

RoHS

Key Commercial Data

Packing unit	12 pc
Minimum order quantity	12 pc
GTIN	 4 046356 193443
GTIN	4046356193443

Technical data

General

Note	Order information: Order contact inserts and cable clamping/shield accessories separately
Mounting type	Central fixing

Ambient conditions

Ambient temperature	-20 °C ... 125 °C
Degree of protection	IP67

Material

Housing material	Turned parts: copper zinc alloy (CuZn), die-cast parts: zinc (GD-Zn)
Gasket and O-ring material	FPM

Specifications according to DIN EN 61984:2001

Installation height max.	2000 m
--------------------------	--------

Environmental Product Compliance

REACH SVHC	Lead 7439-92-1
China RoHS	Environmentally Friendly Use Period = 50



Rear panel feed-through - RC-0000000Q0FZ - 1592924

Technical data


Environmental Product Compliance

	For details about hazardous substances go to tab "Downloads", Category "Manufacturer's declaration"
--	---


Drawings

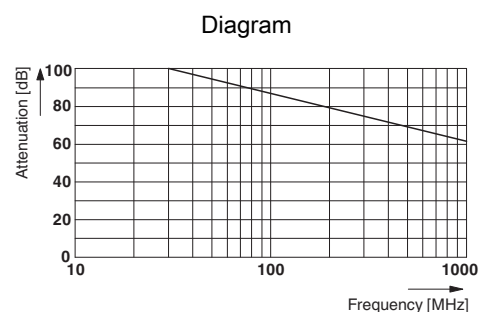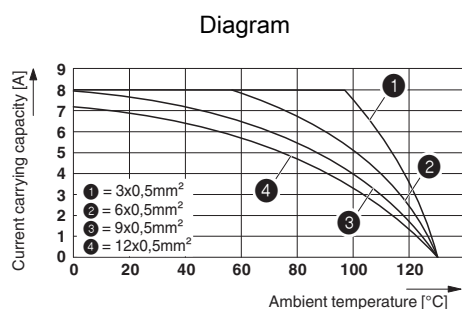

Dimensional drawing

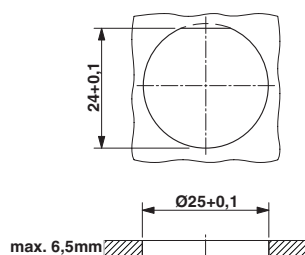

Dimensional drawing

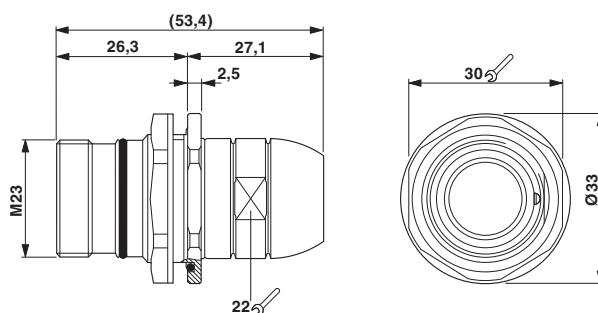

Approvals

Approvals

Approvals

EAC

Rear panel feed-through - RC-0000000Q0FZ - 1592924

Approvals

Ex Approvals

Approval details

EAC		B.01742
-----	---	---------

Phoenix Contact 2018 © - all rights reserved
<http://www.phoenixcontact.com>

PHOENIX CONTACT GmbH & Co. KG
Flachsmarktstr. 8
32825 Blomberg
Germany
Tel. +49 5235 300
Fax +49 5235 3 41200
<http://www.phoenixcontact.com>

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Phoenix Contact:

1592924