


MK3DS 1,5/ 9-5,08 BK - 1016294

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)

PCB terminal block, pitch: 5.08 mm, number of positions: 9, connection method: Screw connection with tension sleeve, mounting: Wave soldering, color: black

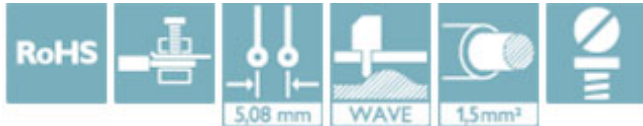

Key Commercial Data

Packing unit	1
GTIN	 4 055626 498133
GTIN	4055626498133
Custom tariff number	85369010

Technical data

Item properties

Number of positions	9
Drive form screw head	Slotted
Pin layout	Linear pinning

Dimensions for the product

Length [l]	32.3 mm
Width [w]	48.26 mm
Height [h]	40.1 mm
Pitch	5.08 mm
Height (without solder pin)	36.6 mm
Solder pin [P]	3.5 mm
Dimension a	40.64 mm

Dimensions for PCB design

Hole diameter	1.3 mm
---------------	--------

Packaging information

Pieces per package	25
Denomination packing units	Pcs.

Environmental Product Compliance

REACH SVHC	Lead 7439-92-1
China RoHS	Environmentally Friendly Use Period = 50

MK3DS 1,5/ 9-5,08 BK - 1016294

Technical data

Environmental Product Compliance

	For details about hazardous substances go to tab "Downloads", Category "Manufacturer's declaration"
--	---

Classifications

eCl@ss

eCl@ss 5.1	27261100
eCl@ss 6.0	27261100
eCl@ss 7.0	27440401
eCl@ss 8.0	27440401
eCl@ss 9.0	27440401

ETIM

ETIM 5.0	EC002643
ETIM 6.0	EC002643

Approvals

Approvals

Approvals

CSA / UL Recognized / cUL Recognized / IECCE CB Scheme / SEV / EAC / cULus Recognized

Ex Approvals

Approval details

CSA		http://www.csagroup.org/services-industries/product-listing/	13631
	D	B	
Nominal voltage UN	300 V	300 V	
Nominal current IN	10 A	10 A	
mm²/AWG/kcmil	24-14	24-14	

UL Recognized		http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm	FILE E 60425
	D	B	
Nominal voltage UN	300 V	125 V	

MK3DS 1,5/ 9-5,08 BK - 1016294

Approvals

	D	B
Nominal current I _N	10 A	10 A
mm ² /AWG/kcmil	30-14	30-14

cUL Recognized				http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm	FILE E 60425
	D	B			
Nominal voltage UN	300 V	125 V			
Nominal current IN	10 A	10 A			
mm²/AWG/kcmil	30-14	30-14			

IECEE CB Scheme			http://www.iecee.org/	CH-8225
Nominal voltage UN		250 V		
Nominal current IN		17.5 A		
mm²/AWG/kcmil		2.5		

SEV		https://www.electrosuisse.ch/de/meta/shop/produktezertifikate.html	IK-3542-M1
Nominal voltage UN	250 V		
Nominal current IN	17.5 A		
mm²/AWG/kcmil	2.5		

EAC		B.01742
-----	---	---------

cULus Recognized	
------------------	---

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Phoenix Contact:](#)

[1016294](#)