



SPECIFICATIONS		
PARAMETERS	VALUES	UNITS
RESONANT FREQUENCY	4,600 ± 500	Hz
RESONANT IMPEDANCE (MAX)	250	Ohm
MAX INPUT VOLTAGE	30	Vp-p
CAPACITANCE @ 100 HZ	16,000 ±30%	pF
PLATE MATERIAL	BRASS	-
OPERATING TEMPERATURE	-20 ~ +60	°C
STORAGE TEMPERATURE	-20 ~ +70	°C

THIS DOCUMENT CONTAINS DATA PROPRIETARY TO  
PROJECTS UNLIMITED, INC. ANY USE OR  
REPRODUCTION, IN ANY FORM, WITHOUT PRIOR  
WRITTEN PERMISSION OF PROJECTS UNLIMITED,  
INC. IS PROHIBITED.

©2003. Projects Unlimited Inc.

REVISION HISTORY			
LTR	DESCRIPTION	DATE	APPROVED
-	RELEASED FROM ENGINEERING	11/6/2007	
A	REVISED TO INVENTOR 3-D DRAWING TEMPLATE	5/10/2013	B.R.
B	UPDATED HEIGHT DIMENSIONS	5/25/2017	M.L.
C	REVISED CAPACITANCE FREQUENCY AND STORAGE TEMPERATURE	2/12/2020	M.V.


REVISION HISTORY			
LTR	DESCRIPTION	DATE	APPROVED
-	RELEASED FROM ENGINEERING	11/6/2007	
A	REVISED TO INVENTOR 3-D DRAWING TEMPLATE	5/10/2013	B.R.
B	UPDATED HEIGHT DIMENSIONS	5/25/2017	M.L.
C	REVISED CAPACITANCE FREQUENCY AND STORAGE TEMPERATURE	2/12/2020	M.V.

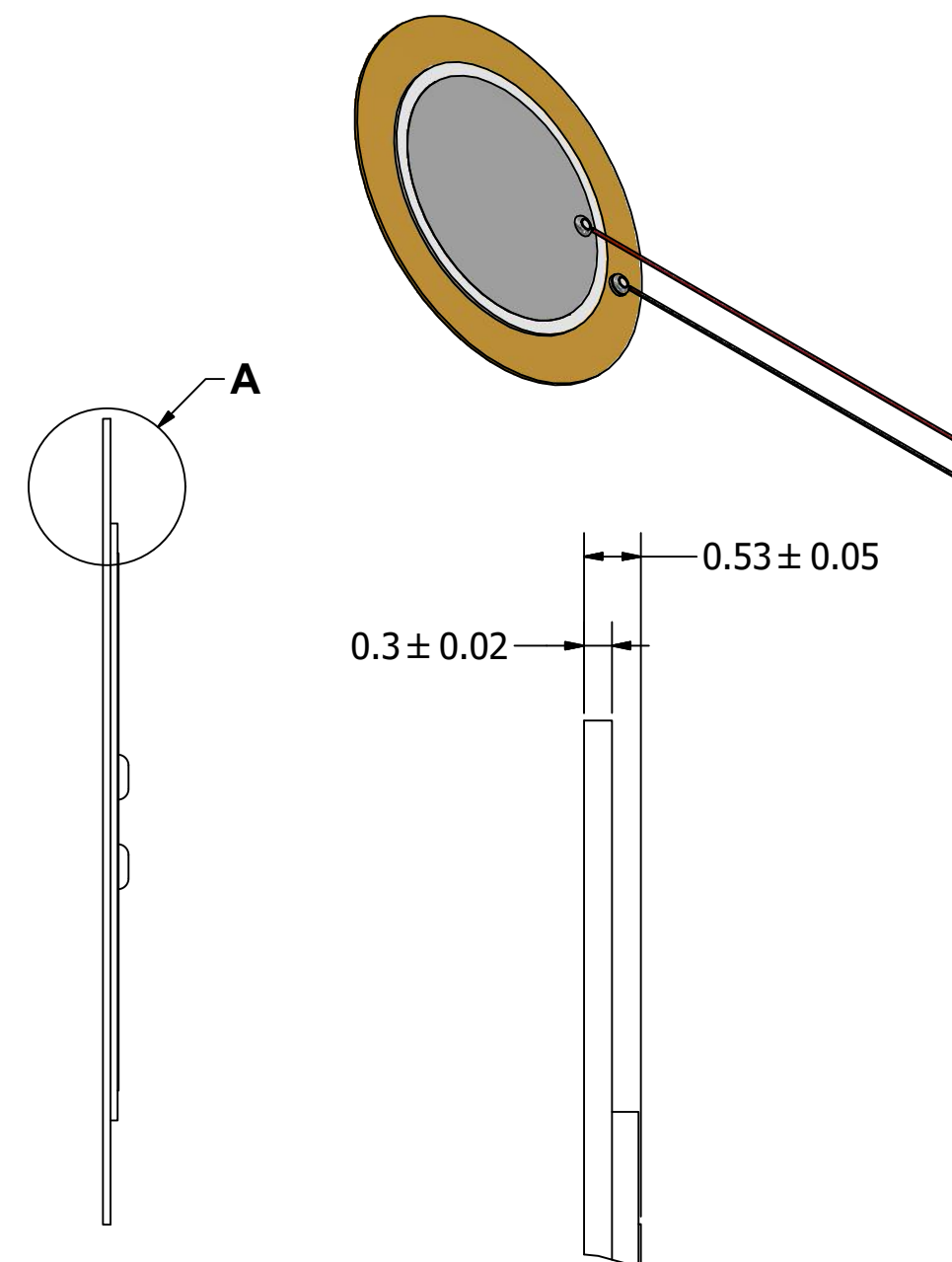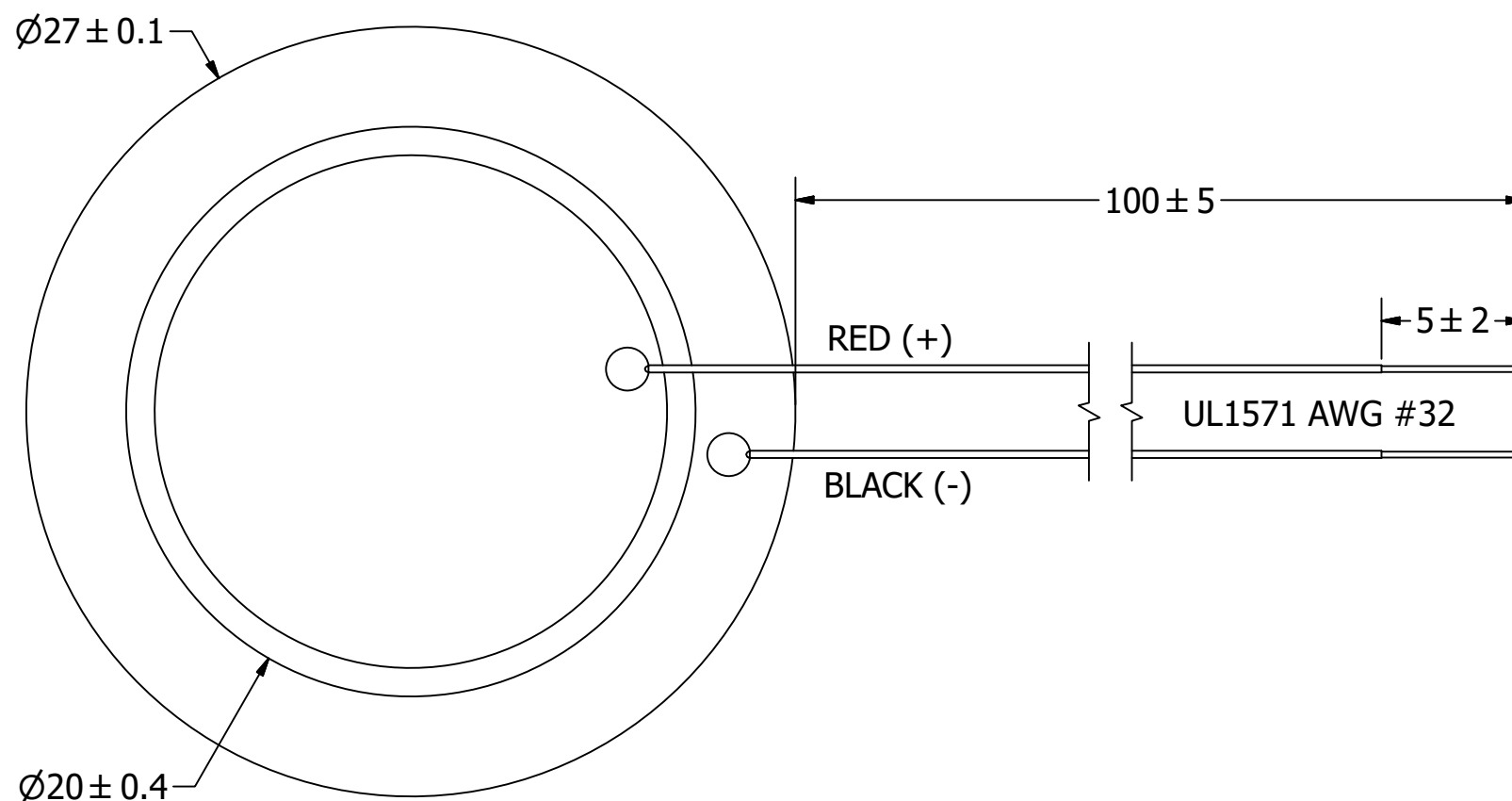

**A ( 15 : 1 )**

**NOTES:**

1. ALL DIMENSIONS ARE IN MILLIMETERS.
2. SPECIFICATIONS SUBJECT TO CHANGE OR WITHDRAWAL WITHOUT NOTICE.
3. THIS PART IS RoHS 2011/65/EU COMPLIANT.

UNLESS OTHERWISE SPECIFIED:  DIMENSIONS ARE IN MILLIMETERS,  TOLERANCES ARE ±0.5 AND ANGLES ARE ±3°.	SIZE	Designed by	Date	Checked by	Date	Approved by	Date	Drawn Date	
		J.D.	5/9/2013	C.W.	5/9/2013	B.R.	5/9/2013	5/9/2013	
	A3	 <b>pui audio</b> ™ inc			AB2746B-LW100-R				
					Bender				
AB2746B-LW100-R.idw									

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[PUI Audio:](#)

[AB2746B-LW100-R](#)