


SPECIFICATIONS		
PARAMETERS	VALUES	UNITS
RATED VOLTAGE	12	Vdc
OPERATING VOLTAGE RANGE	1.5 ~ 20	Vdc
RATED CURRENT (MAX)	10	mA
MINIMUM SPL @ 10 CM	106	dBA
RESONANT FREQUENCY	2,800 ± 500	Hz
tone or pulse rate	CONTINUOUS	0 pulse/sec
OPERATING TEMPERATURE	-20 ~ +60	°C
STORAGE TEMPERATURE	-30 ~ +70	°C
HOUSING MATERIAL	ABS	-
TERMINAL MATERIAL	LEAD WIRE	-
WEIGHT	15	grams

THIS DOCUMENT CONTAINS DATA PROPRIETARY TO PROJECTS UNLIMITED, INC. ANY USE OR REPRODUCTION, IN ANY FORM, WITHOUT PRIOR WRITTEN PERMISSION OF PROJECTS UNLIMITED, INC. IS PROHIBITED.

©2003, Projects Unlimited Inc.

REVISION HISTORY			
LTR	DESCRIPTION	DATE	APPROVED
-	RELEASED FROM ENGINEERING	11/8/2005	
A	REVISED COLOR OF WIRE LEADS	10/11/2007	R.W.
B	REVISED GAUGE OF WIRE LEADS	7/3/2008	B.R.
C	REVISED TO INVENTOR 3-D DRAWING TEMPLATE	1/14/2011	B.R.
D	ADD NOTE 4	8/26/2014	B.R.
E	REVISED VOLTAGE RANGE	2/24/2020	M.V.

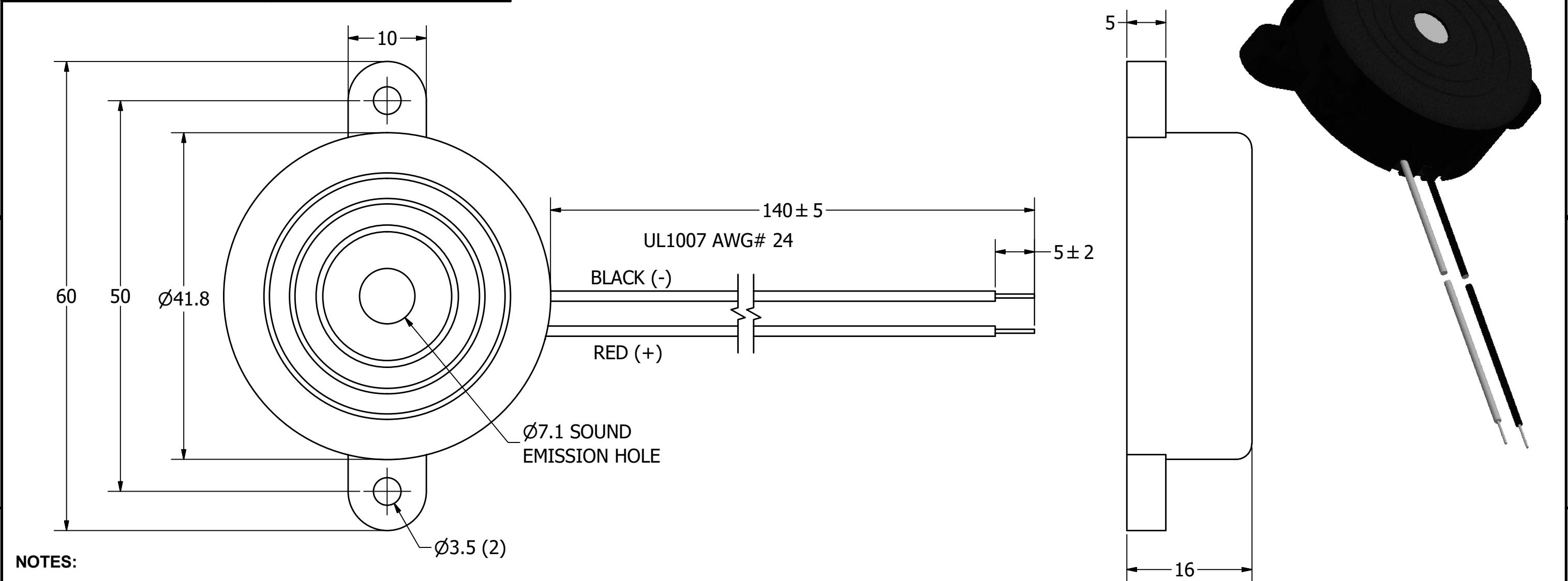

- NOTES:
- ALL DIMENSIONS ARE IN MILLIMETERS.
 - SPECIFICATIONS SUBJECT TO CHANGE OR WITHDRAWL WITHOUT NOTICE.
 - THIS PART IS RoHS 2011/65/EU COMPLIANT.
 - ALL INTERNAL COMPONENTS UPDATED TO SMD.

UNLESS OTHERWISE SPECIFIED: DIMENSIONS ARE IN MILLIMETERS, TOLERANCES ARE ±0.5 AND ANGLES ARE ±3°.	SIZE A3	Designed by	Date	Checked by	Date	Approved by	Date	Drawn Date	
		J.A.F.	11/8/2005	B.R.	11/9/2005	E.P.	11/9/2004	10/10/2008	
	AI-4228-TF-LW140-3-R.idw	 pui audio [™] a projects unlimited company	AI-4228-TF-LW140-3-R					Indicator	Edition -

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[PUI Audio:](#)

[AI-4228-TF-LW140-3-R](#)