



THIS DOCUMENT CONTAINS DATA PROPRIETARY TO PROJECTS UNLIMITED, INC. ANY USE OR REPRODUCTION, IN ANY FORM, WITHOUT PRIOR WRITTEN PERMISSION OF PROJECTS UNLIMITED, INC. IS PROHIBITED.
© 2005, Projects Unlimited Inc.

SPECIFICATIONS

| PARAMETERS | VALUES | UNITS |
|---|--------------|-------|
| RATED INPUT POWER | 1.5 | W |
| MAX INPUT POWER | 2 | W |
| IMPEDANCE | 4±15% | OHM |
| OUTPUT SPL @ 1W/1M (AT 0.8, 1.0, 1.2, 1.5 kHz) | 82±3 | dBA |
| DISTORTION (MAX.) | 5% | — |
| RESONANT FREQUENCY | 550±20% | Hz |
| FREQUENCY RANGE | 550 ~ 11,000 | Hz |
| HOUSING MATERIAL | METAL | — |
| CONE MATERIAL | MYLAR | — |
| MAGNET MATERIAL | Nd-Fe-B | — |
| OPERATING TEMPERATURE | -20 ~ +60 | °C |
| WEIGHT | 8.25 | grams |

REVISIONS

| LTR | DESCRIPTION | DATE | APPROVED |
|-----|---------------------------|---------|----------|
| — | RELEASED FROM ENGINEERING | 6/28/10 | |

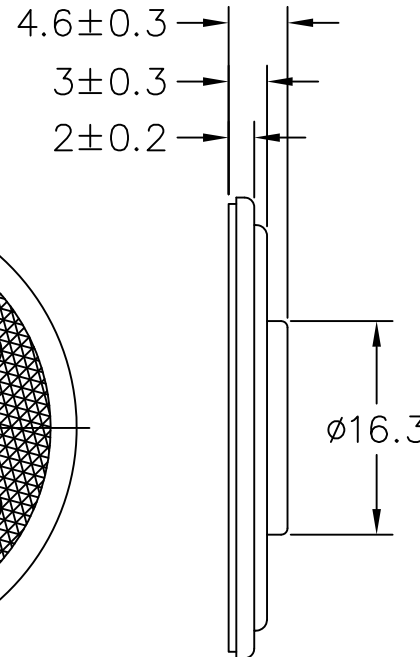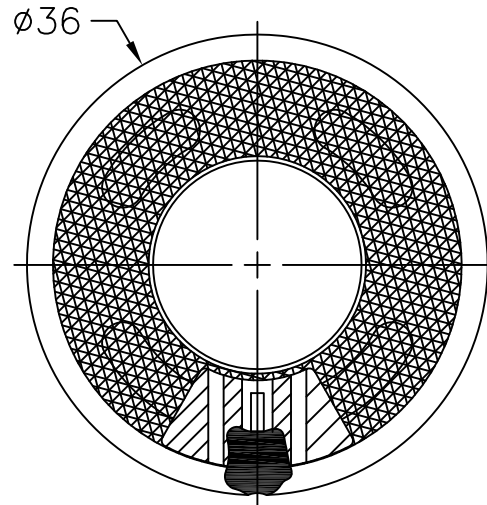

NOTES:

- ALL DIMENSIONS ARE IN MILLIMETERS.
- SPECIFICATION SUBJECT TO CHANGE OR WITHDRAWAL WITHOUT NOTICE.
- THIS PART IS RoHS 2002/95/EC COMPLIANT.

FILE NAME
AS03604MR-2-R.DWG

UNLESS OTHERWISE SPECIFIED:
DIMENSIONS ARE IN
MILLIMETERS, TOLERANCES ARE ±0.5 AND
ANGLES ARE ±3°.



6300 Sand Lake Road
Dayton, Ohio 45414

| APPROVALS | | DATE | SPEAKER | |
|-----------|------|------|---------------|---------------|
| DRAWN | J.D. | 6/10 | SIZE | DRAWING NO. |
| CHECKED | C.W. | 6/10 | A | AS03604MR-2-R |
| APPROVED | B.R. | 6/10 | SCALE: N.T.S. | SHEET 1 OF 1 |

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[PUI Audio:](#)

[AS03604MR-2-R](#)