


THIS DOCUMENT CONTAINS DATA PROPRIETARY TO PROJECTS UNLIMITED, INC. ANY USE OR REPRODUCTION, IN ANY FORM, WITHOUT PRIOR WRITTEN PERMISSION OF PROJECTS UNLIMITED, INC. IS PROHIBITED.
© 2005, Projects Unlimited Inc.

SPECIFICATIONS

PARAMETERS	VALUES	UNITS
RATED INPUT POWER	1.0	W
MAX INPUT POWER	1.5	W
IMPEDANCE	8±15%	OHM
OUTPUT SPL @ 1W/1M	89±3	dBA
RESONANT FREQUENCY	630±20%	Hz
FREQUENCY RANGE	F _o ~ 6000	Hz
FRAME MATERIAL	SPCC W/ZINC PLATING	—
CONE MATERIAL	MYLAR	—
MAGNET MATERIAL	NdFeB	—
OPERATING TEMPERATURE	-20 ~ +60	°C

REVISIONS

LTR	DESCRIPTION	DATE	APPROVED
—	RELEASED FROM ENGINEERING	6/6/17	—
A	ADDED FRAME MATERIAL AND POLARITY	8/23/18	M.V.
B	ADDED NOTE 4 REGARDING TERMINALS	8/27/18	M.V.

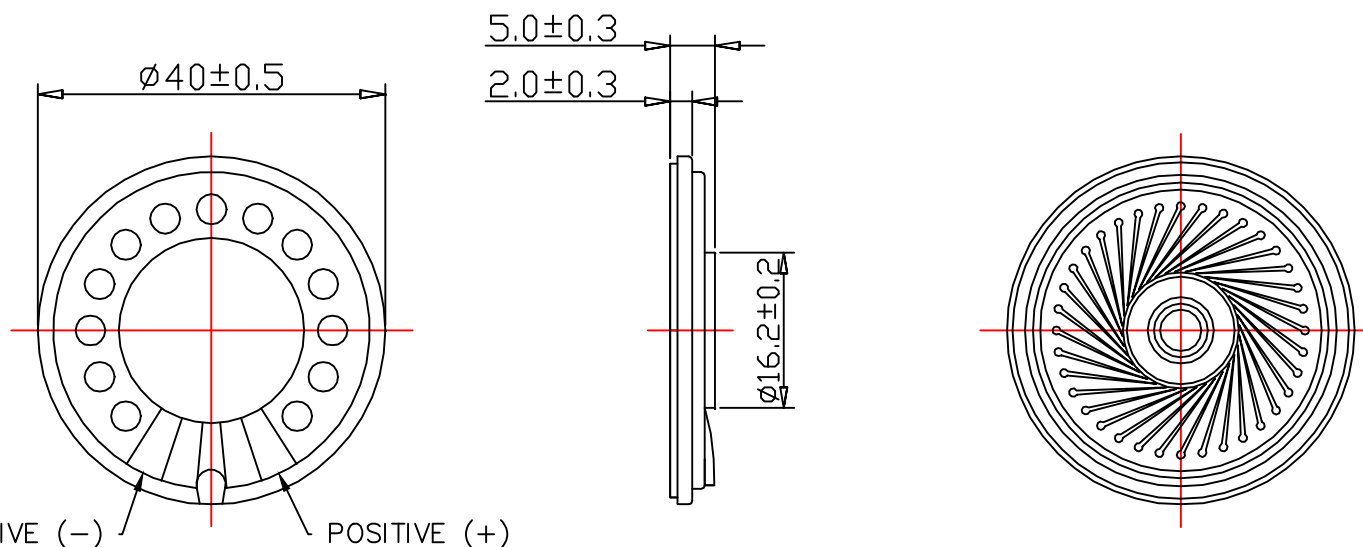

NOTES:

1. ALL DIMENSIONS ARE IN MILLIMETERS.
2. SPECIFICATION SUBJECT TO CHANGE OR WITHDRAWAL WITHOUT NOTICE.
3. THIS PART IS RoHS 2011/65/EU COMPLIANT.
4. SOLDER TERMINALS ARE TIN PLATED COPPER WITH LEAD-FREE SOLDER (SnCu) PRE-APPLIED.

NEGATIVE (-) POSITIVE (+)

FILE NAME
AS04008MR-21-R.DWG

UNLESS OTHERWISE SPECIFIED:

ALL PURCHASES ARE SUBJECT TO THE PUI AUDIO TERMS AND CONDITIONS SALE FOUND AT http://www.puiaudio.com/pdf/terms_conditions.pdf (paper copy available upon request).

DIMENSIONS ARE IN MILLIMETERS, TOLERANCES ARE ± 0.5 AND ANGLES ARE $\pm 3^\circ$.



3541 Stop Eight Road
Dayton, Ohio 45414

APPROVALS		DATE	SPEAKER	
DRAWN	M. V.	6/17	SIZE	DRAWING NO.
CHECKED	M. V.	6/17	A	AS04008MR-21-R
APPROVED	B. R.	6/17	SCALE: N.T.S.	SHEET 1 OF 1

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

PUI Audio:

[AS04008MR-21-R](#) [SMT-1027-S-HT-R](#)