


THIS DOCUMENT CONTAINS DATA PROPRIETARY TO PROJECTS UNLIMITED, INC. ANY USE OR REPRODUCTION, IN ANY FORM, WITHOUT PRIOR WRITTEN PERMISSION OF PROJECTS UNLIMITED, INC. IS PROHIBITED.
© 2005, Projects Unlimited Inc.

SPECIFICATIONS

PARAMETERS	VALUES	UNITS
RATED INPUT POWER	20	W
MAX INPUT POWER	40	W
IMPEDANCE	8±15%	OHM
OUTPUT SPL @ 2.83V/1M	84±2	dBA
RESONANT FREQUENCY	80±20%	Hz
FREQUENCY RANGE	80 ~ 15,000	Hz
FRAME MATERIAL	STAMPED STEEL	—
CONE MATERIAL	ALUMINUM	—
MAGNET MATERIAL	FERRITE	—
OPERATING TEMPERATURE	-20 ~ +60	°C
WEIGHT	640	grams

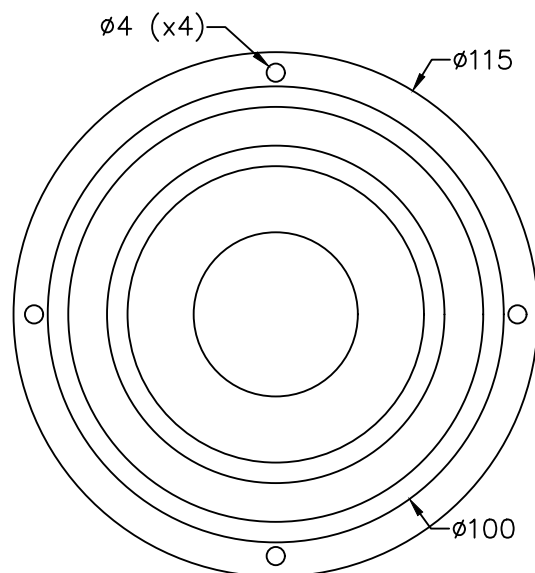


NOTES:

1. ALL DIMENSIONS ARE IN MILLIMETERS.
2. SPECIFICATION SUBJECT TO CHANGE OR WITHDRAWAL WITHOUT NOTICE.
3. THIS PART IS RoHS 2011/65/EU COMPLIANT.
4. QTS: 0.66, VAS: 2.45L, XMAX: 3.5MM

FILE NAME
AS11508AR-R.DWG

REVISIONS

LTR	DESCRIPTION	DATE	APPROVED
—	RELEASED FROM ENGINEERING	8/5/16	

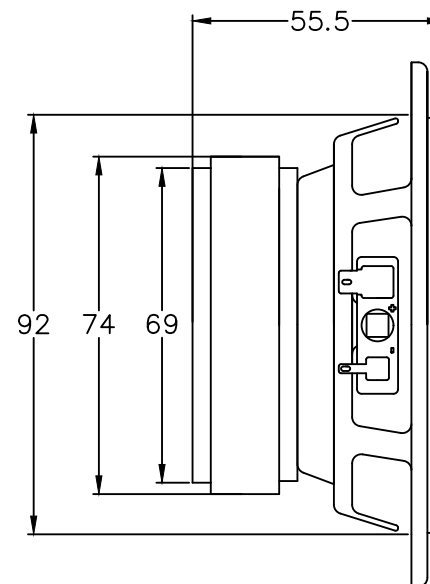

UNLESS OTHERWISE SPECIFIED:
ALL PURCHASES ARE SUBJECT TO THE PUI AUDIO TERMS AND CONDITIONS SALE FOUND AT http://www.puiaudio.com/pdf/terms_conditions.pdf (paper copy available upon request).
DIMENSIONS ARE IN MILLIMETERS. TOLERANCES ARE ±0.5 AND ANGLES ARE ±3°.



3541 Stop Eight Road
Dayton, Ohio 45414

APPROVALS	DATE	SIZE	DRAWING NO.
DRAWN <i>M. V.</i>	3/16	A	AS11508AR-R
CHECKED <i>M. V.</i>	3/16		
APPROVED <i>B. R.</i>	3/16		
SCALE: N.T.S.		SHEET 1 OF 1	

WOOFER

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[PUI Audio:](#)

[AS11508AR-R](#)