

SPECIFICATIONS

PARAMETERS	VALUES	UNITS
RATED VOLTAGE (SQUARE WAVE)	3	Vpk
OPERATING VOLTAGE RANGE	2 ~ 5	Vpk
RATED CURRENT (MAX)	80	mA
COIL RESISTANCE	15 ± 3	OHM
MINIMUM SPL @ 10 CM	85	dBA
RESONANT FREQUENCY	2,000 ± 500	Hz
OPERATING TEMPERATURE	-25 ~ +70	°C
STORAGE TEMPERATURE	-30 ~ +80	°C
HOUSING MATERIAL	PPO	-
TERMINAL MATERIAL	Au PLATED BRASS	-
WEIGHT	2	grams





THIS DOCUMENT CONTAINS DATA PROPRIETARY TO
PROJECTS UNLIMITED, INC. ANY USE OR
REPRODUCTION, IN ANY FORM, WITHOUT PRIOR
WRITTEN PERMISSION OF PROJECTS UNLIMITED,
INC. IS PROHIBITED.

©2003, Projects Unlimited Inc.

©2003, Projects Unlimited Inc.

REVISION HISTORY			
TR	DESCRIPTION	DATE	APPROVED

LTR	DESCRIPTION	DATE	APPROVED
-	RELEASED FROM ENGINEERING	2014/07/22	

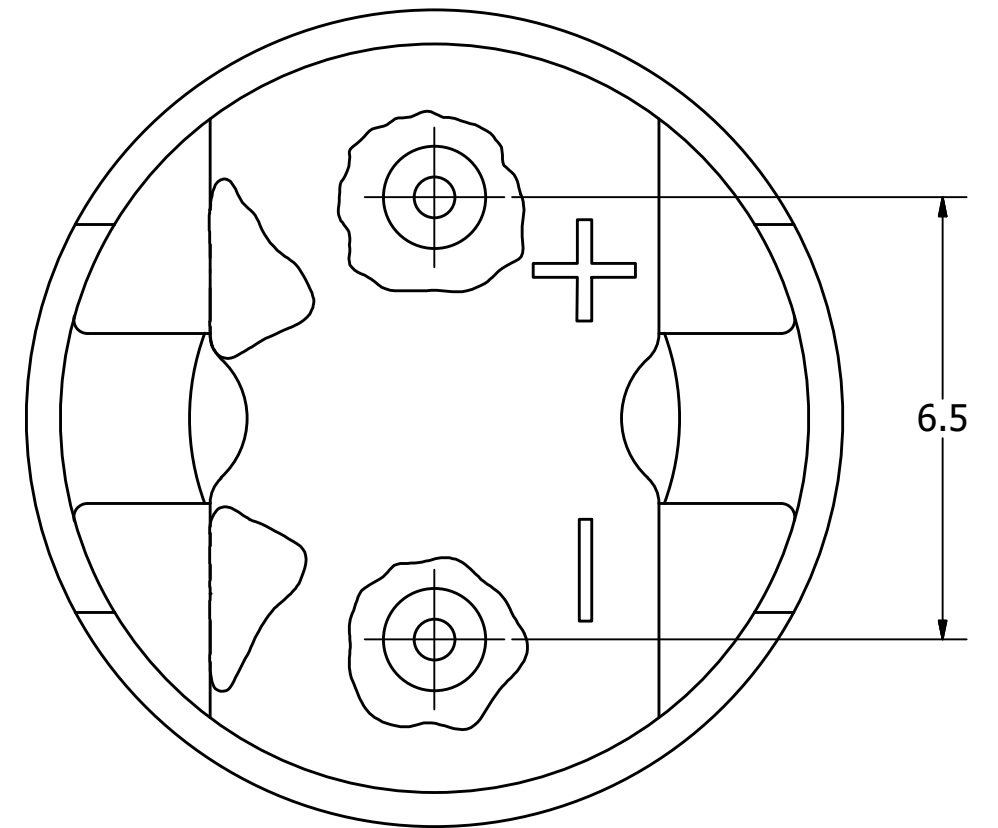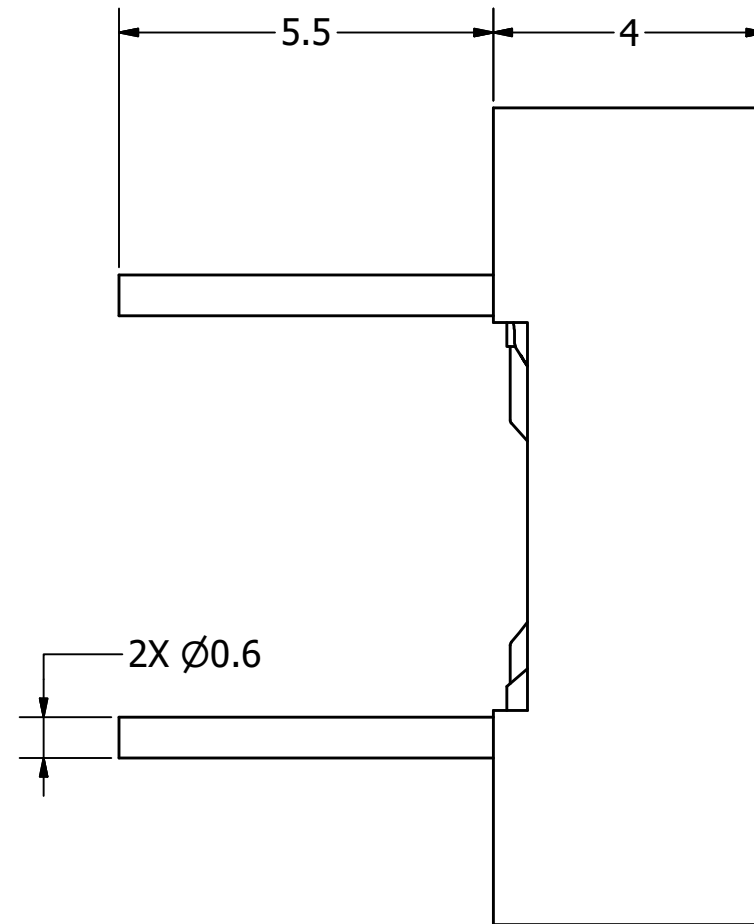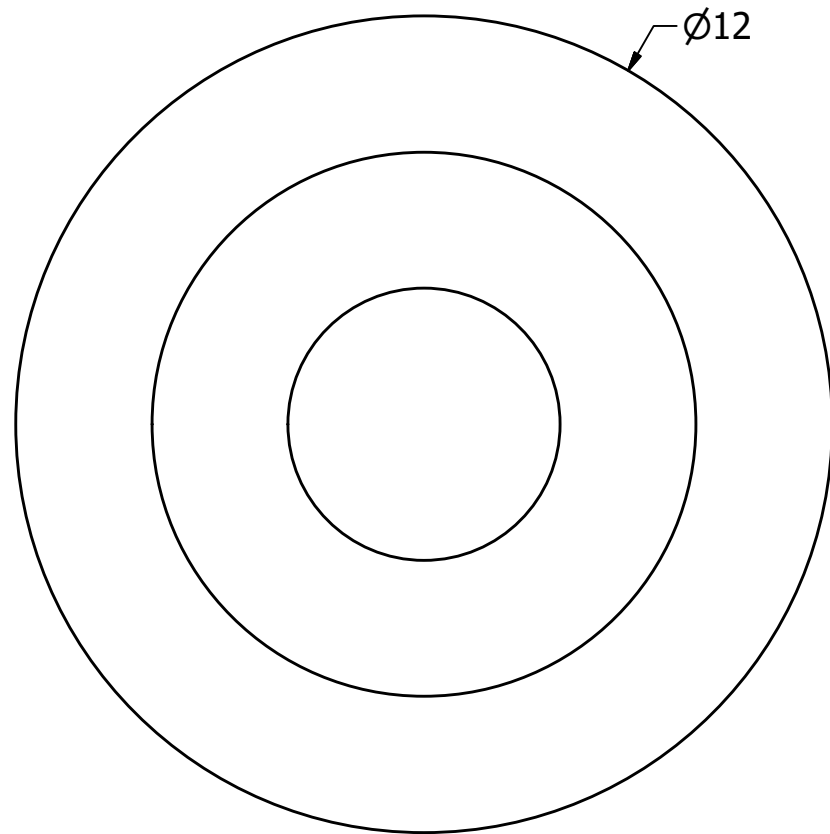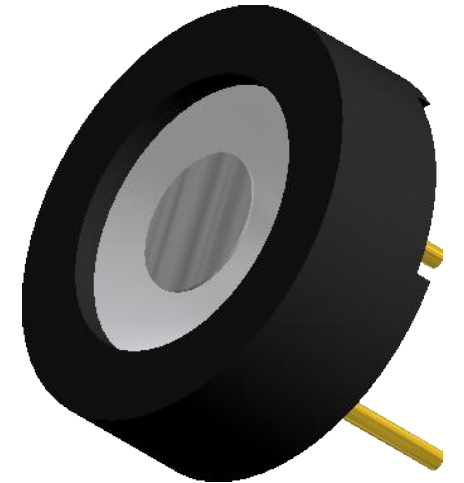


NOTES:


1. ALL DIMENSIONS ARE IN MILLIMETERS.
2. SPECIFICATIONS SUBJECT TO CHANGE OR WITHDRAWAL WITHOUT NOTICE.
3. THIS PART IS RoHS 2011/65/EU COMPLIANT.

UNLESS OTHERWISE SPECIFIED:
ALL PURCHASES ARE SUBJECT TO AND
INCORPORATE THE PUI AUDIO TERMS
AND CONDITIONS SALE FOUND AT
[http://www.puiaudio.com](http://www.puiaudio.com/pdf/terms_conditions.pdf)
[/pdf/terms_conditions.pdf](http://www.puiaudio.com/pdf/terms_conditions.pdf)
 (paper copy available upon request).
DIMENSIONS ARE IN MILLIMETERS,
TOLERANCES ARE ±0.5 AND
ANGLES ARE ±3°.

AT-1220-TT-3V-

SIZE
A3

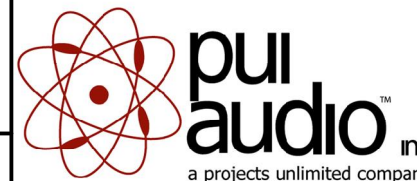

Designed by	Date	Checked by	Date	Approved by	Date	Drawn Date
J.D.	7/22/2014	C.W.	7/22/2014	B.R.	7/22/2014	7/22/2014
 pui audio ™ <small>a projects unlimited company</small>			AT-1220-TT-3V-2-R			
			Transducer (Electro-Mech)		Edition -	Sheet 1 / 1

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[PUI Audio:](#)

[AT-1220-TT-3V-2-R](#)