

12 Series

RoHS
Compliant


NYLON 6.6

GENERAL PURPOSE

MATERIAL OPERATING TEMPERATURE: -40°C to +85°C

APPLICATION OPERATING TEMPERATURE: -10°C to +85°C

Part Number	Width mm [Inch]	Length mm [Inch]	Max Bundle Diameter mm [Inch]	Min Loop Tensile Kg [lb]
S - 50lb				
12-S200	4.8 [.189]	200 [7.9]	57.1 [2.15]	22 [50]
12-S300	4.8 [.189]	300 [11.8]	85.3 [3.36]	22 [50]

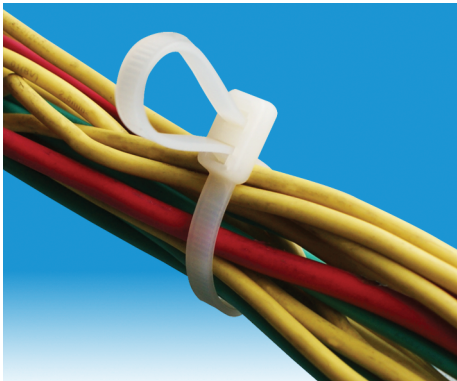

PART NUMBER SYSTEM

12 - S 200 B - C

SERIES

CROSS SECTION


LENGTH

MATERIAL/COLOR

N: Natural
B: Normal UV Black

PACKAGE SIZE

C: 100PCS
Number: Other Quantity

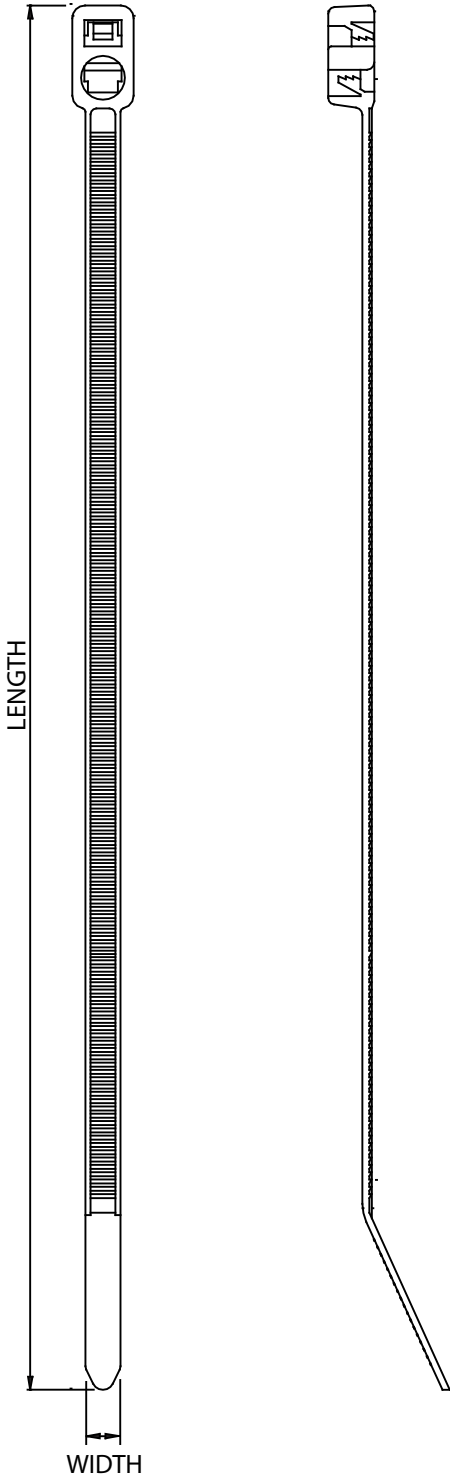

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Qualtek:

[12-S200B-C](#) [12-S200N-C](#) [12-S300B-C](#) [12-S300N-C](#)