

15 Series

RoHS
Compliant

NYLON 6.6

GENERAL PURPOSE

 

APPLICATION OPERATING TEMPERATURE: -40°C to +85°C

APPROVALS¹: c  US



Part Number	Length mm [Inch]	Width mm [Inch]	Screw Size	Cable Ties Width up to mm [Inch]
15-1919	19.0 [.750]	19.0 [.750]	M5 [#10]	3.6 [.140]
15-2525	28.0 [1.10]	28.0 [1.10]	M5 [#10]	4.8 [.189]
15-4040	40.0 [1.50]	40.0 [1.50]	M5 [#10]	9.0 [.354]

Notes:
1. 15-4040 is not UL approved

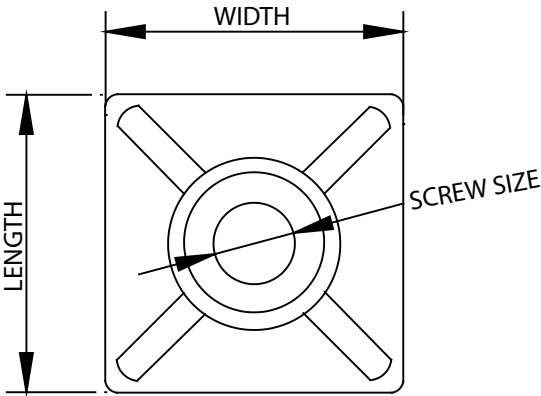

PART NUMBER SYSTEM

15 - 1919 B - C

SERIES

SIZE

MATERIAL/COLOR

N: Natural
B: Normal UV Black

PACKAGE SIZE

C: 100PCS
Number: Other Quantity

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Qualtek:](#)

[15-1919B-C](#) [15-1919N-C](#) [15-2525B-C](#) [15-2525N-C](#) [15-4040B-C](#) [15-4040N-C](#)