



THESE DRAWINGS ARE THE PROPERTY OF QUALTEK ELECTRONICS AND NOT TO BE REPRODUCED FOR OR COMMUNICATED TO A THIRD PARTY WITHOUT THE EXPRESS WRITTEN PERMISSION OF AN OFFICER OF QUALTEK ELECTRONICS.

REVISION			
REV.	DESCRIPTION	DATE	APPROVED

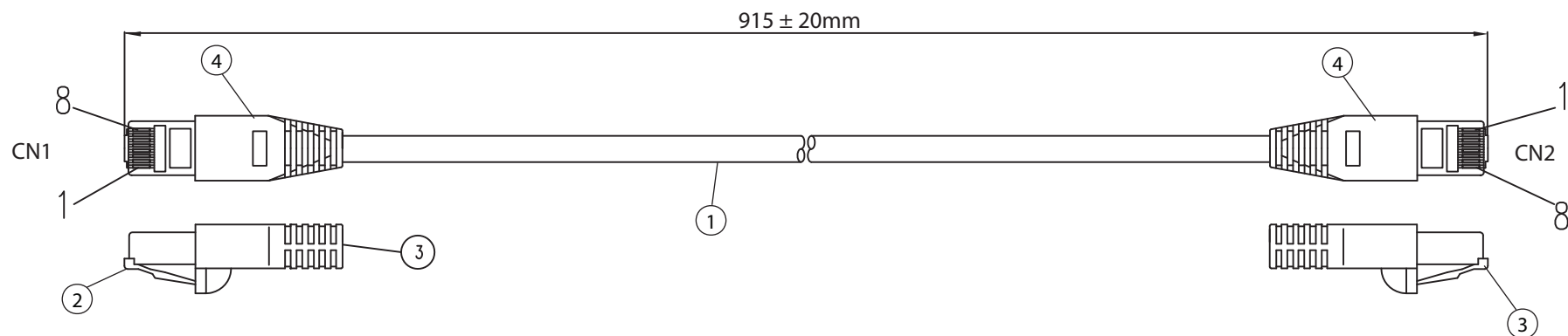

#### CONNECTION

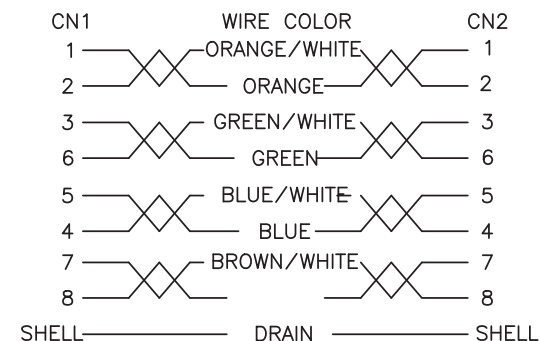

#### NOTES:

- CABLE: UL 2835 STP CAT-5e 350MHz  
24AWG\*4PR+AE  
OUTER JACKET: WHITE OD: 5.5 ± 0.2mm
- CONNECTOR: RJ45 8P8C  
CONTACT PHOSPHOR BRONZE  
GOLD PLATED G/F  
SHELL NICKEL PLATED
- CONNECTOR: RJ45 8P8C  
CONTACT PHOSPHOR BRONZE  
GOLD PLATED G/F  
SHELL NICKEL PLATED
- PVC MOLDED HOOD: COLOR WHITE
- ELECTRICAL TEST:  
<1>.100% OPEN SHORT & MISS WIRE TEST  
<2>.INSULATION RESISTANCE: DC300V 20M ohm MIN.  
<3>.CONDUCTOR RESISTANCE: 2 ohm MAX.

**CONTROLLED**

Dim range (mm)		Qualtek Electronics Corp. WCI DIVISION		
Tolerance +/- (mm)		Part Number: 1221021-03 <span style="border: 1px solid green; padding: 2px;">RoHS Compliant</span>		
0-1	0.15	Description: 8P8C - 8P8C		
1-6	0.20			
6-18	0.30	RFQ# 2505H	UNIT: mm	
18-50	0.50			
50-120	0.70	Drawn / Date	Checked / Date	Approved / Date
120-250	0.90	R. Nuti 07-15-13	07-15-13	LY / 07-15-13
250-500	1.20			

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Qualtek:](#)

[1221021-03](#)