




- [Home](#)
- [Products](#)
- [Online Catalog](#)
- [Request Quote](#)
- [Order Online](#)
- [Check Stock](#)
- [Request Print Catalog](#)
- [Request Samples](#)
- [Engineering Data](#)
- [Distributors](#)
- [Capabilities Brochure](#)

[Home](#) > [1/4 Round Swage Standoffs](#)

## 1/4 ROUND SWAGE STANDOFFS

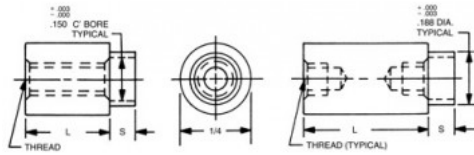

[Home](#) [Previous](#) [Next](#)  
[Related Metric](#)

Ordering Code				
xxxxx	x	xxx	xx	x
Length		Thread		Finish
	Shank		Material	

**PART: 3045-C-632-B-16**

Red ?'s show missing selections. [Help](#)

[Thread depth information](#)  
[Material Specifications](#)  
[Ordering non-standard items](#)

**Add to Cart**

Qty1 \*  Qty2  Qty3

**Length \***

Select	Part No.	Length
<input type="radio"/>	3045A	3/32
<input checked="" type="radio"/>	3045	1/8
<input type="radio"/>	3045T	5/32
<input type="radio"/>	3046	3/16
<input type="radio"/>	3046T	7/32
<input type="radio"/>	3047	1/4
<input type="radio"/>	3047T	9/32

**Shank \***

Select	S	0.003-0.003	P
<input type="radio"/>	A	.075	1/32
<input type="radio"/>	B	.105	1/16
<input checked="" type="radio"/>	C	.135	3/32
<input type="radio"/>	D	.165	1/8
<input type="radio"/>	E	.230	3/16
<input type="radio"/>	F	.290	1/4

**Thread \***

Select	Code	Thread
<input type="radio"/>	256	2-56
<input type="radio"/>	348	3-48
<input type="radio"/>	440-4-40	
<input checked="" type="radio"/>	632	6-32

**Material \***

Select	Code	Material	RoHS
<input type="radio"/>	AL	Aluminum	YES
<input checked="" type="radio"/>	B	Brass	YES
<input type="radio"/>	SS	Stainless Steel	YES
<input type="radio"/>	S	Steel	YES

- 12-Zinc
- 13-Bright dip - brass
- 14-Bright tin/copper flash
- 15-Hot tin dip\*
- 16-Electro tin
- 19-Caustic etch
- 20-Passivation
- 21-Dark grey anodize
- 22-Clear anodize
- 23-Yellow green anodize
- 24-Black anodize
- 25-Black oxide brass
- 26-Black oxide SS
- 27-Electro tin solder 60/40





# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

## RAF Electronic Hardware:

[3045-B-632-B](#) [3047-B-632-B](#) [3046-B-440-B](#) [3045T-B-440-AL](#) [3047-B-632-SS](#) [3046-C-440-AL](#) [3045-a-632-al](#) [3045-b-440-b](#) [3046-b-632-al](#) [3047-b-440-b](#) [3047-b-632-al](#)