

384 **0%**
MERCURY

SR736SW (SR41)
Watch Battery OEM
Swiss Made

Technical Data Sheet


Specifications

Chemical system	Zinc / Monovalent Silver Oxide, low drain
Nominal Voltage	1,55 V
Capacity	45 mAh, Discharge over 18,2 k Ω at 20°C to 1,2 V
Operating Temperature*	-10°C – 60°C
Self Discharge	Less than 5% per year at 20°C
Weight	~0,66 g

Dimensions


(according IEC 60086-3)

Diameter	7,90 mm (0,311")
Height	3,60 mm (0,142")

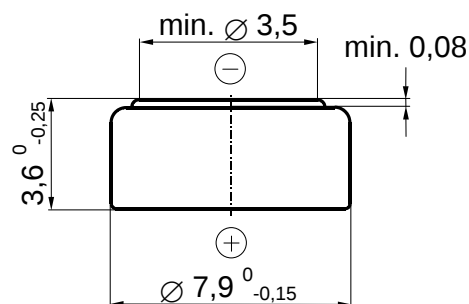

Discharge Curve

Constant Load	18,2 k Ω
Starting Drain	83,0 μ A
Temperature	20°C

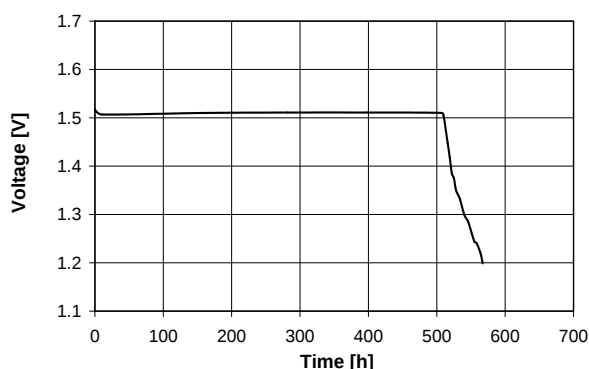

Information and contents in this data sheet are for reference purpose only. They do not constitute any warranty or representation and are subject to change without notice. For most current information and further details, please contact your Renata representative. For safety related information please consult the PSDS document related to that product or product family.

*Condensing humidity not allowed

Rev. 384MF_OEM.05 2017/07

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Renata:

384.IB0%HG