
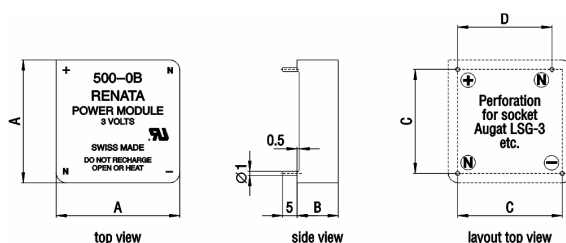


Power Modules

Power Modules Horizontal Versions for Plug-in (cont.)

Without decoupling diodes

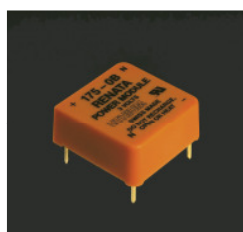

RENATA No.	Nominal capacity (mAh)	Nominal voltage (V)	Encapsulated cell	Weight (g)	Maximum dimensions (mm)			
					A	B	C	D
175-0B	225	3	CR2032MFR	6.5	22.0	8.0	17.8	15.3
1000-0B	950	3	CR2477N	15.0	30.0	10.0	25.4	22.9

Operating temperature range:

Self-discharge rate:

Specifications - module housings:
- plug-in pins:

-30°C to +70°C (Module 175) ; -40°C to +85°C (Module 1000)
less than 1% per year at 25°C
polyamide 66
gold plated

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Renata:](#)

[1000-0B](#)