



# Series LP300 Programmers and Shorting Plugs

## FEATURES:

- Shorting plugs mate with any .300 [7.62] center DIP socket to provide custom programming.
- Stacks on .100 [2.54] centers.
- Converts any socket into a DIP switch.

## SPECIFICATIONS:

- Standard plug body material is Black UL94-V/0 4/6 Nylon.
- Pins are 3/4 hard Brass.
- Pin plating is  $10\mu$  [.25 $\mu$ m] min. Gold per MIL-G-45204 over  $50\mu$  [1.27 $\mu$ m] min. Nickel per SAE-AMS-QQ-N-290.
- Current rating=2 Amps.
- Operating temperature= -67° to 257°F [-55°C to 125°C]



*Note: Aries specializes in custom design and production. In addition to the standard products shown on this page, special materials, platings, sizes, and configurations can be furnished, depending on quantities. Aries reserves the right to change product specifications without notice.*


## ALL DIMENSIONS: INCHES [MILLIMETERS]

All tolerances  $\pm .005$  [.13]  
unless otherwise specified

**LP300**  
(LO-PRO®file plug)

## ORDERING INFORMATION

Specify Part No. **LP300**  
for LO-PRO®file plug  
with Gold plating

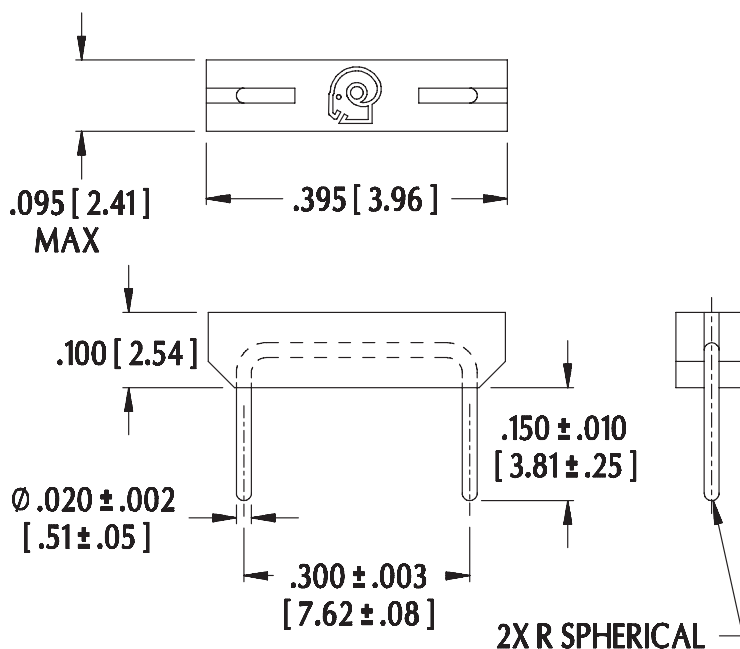

<http://www.arieselec.com> • [info@arieselec.com](mailto:info@arieselec.com)

Bristol, PA USA  
TEL: (215) 781-9956  
FAX: (215) 781-9845



16003  
REV. D

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Aries Electronics:](#)

[LP300T](#) [DP-300](#)