



P/N 1109681-XXX

Mirror Image Collet Socket

FEATURES


- A cost-effective solution for design problems, this socket reroutes connections from a row of female contacts on top, to the opposite row of male pins on bottom.
- IC can be replaced at the opposite side of a PCB.

GENERAL SPECIFICATIONS

- FEMALE SOCKET MATERIAL: black UL 94V-0 glass-filled 4/6 Nylon 170°C continuous use temp.
- PCB: FR-4, 0.062 [1.56] or 0.094 [2.39] thick
- MALE PIN: Brass 360 1/2-hard per UNS C36000, ASTM B16/B16M
- MALE PIN PLATING: 200μ [5.08μ] Sn/Pb 93/7 per ASTM B579-73 over 100μ [2.54μ] Ni per SAE-AMS-QQ-N-290
- FEMALE PIN BODY: Brass 360 1/2-hard per UNS C36000, ASTM B16/B16M
- FEMALE PIN BODY PLATING: 10μ [0.254μ] Au per MIL-G-45204 over 100μ [2.54μ] Ni per SAEAMS-QQ-N-290
- 4-FINGER COLLET CONTACT: BeCu per UNS C17200, ASTM B194-08
- CONTACT PLATING: 10μ [0.254μ] Au per MIL-G-45204 over 50μ [1.27μ] Ni per SAE-AMS-QQ-N-290
- CONTACT CURRENT RATING: 3 amps
- OPERATING TEMPERATURE: 221°F [105°C]
- INSERTION FORCE: 180g/pin
- WITHDRAWAL FORCE: 90g/pin
- NORMAL FORCE: 140g/pin; based on a 0.018 [0.46] dia. test lead
- SOCKET ACCEPTS: leads 0.015-0.025 [0.38-0.64] in dia., 0.100-0.125 [2.54-3.18] long

MOUNTING CONSIDERATIONS

- SUGGESTED PCB HOLE SIZE: 0.028 ±0.003 [0.71 ±0.08] dia.

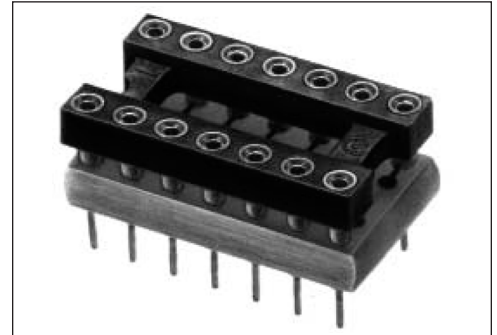

CUSTOMIZATION: In addition to the standard products shown on this page, Aries specializes in custom design and production. Special materials, platings, sizes, and configurations can be furnished, depending on the quantity. **NOTE:** Aries reserves the right to change product general specifications without notice.

ORDERING INFORMATION


Consult Factory – Aries will assign a special P/N

ALL DIMENSIONS: INCHES [MILLIMETERS]

ALL TOLERANCES: ±0.005 [0.13] UNLESS OTHERWISE SPECIFIED

ORDER REQUIREMENT: 100-PIECE MINIMUM

CONSULT FACTORY FOR OTHER SIZES AND CONFIGURATIONS

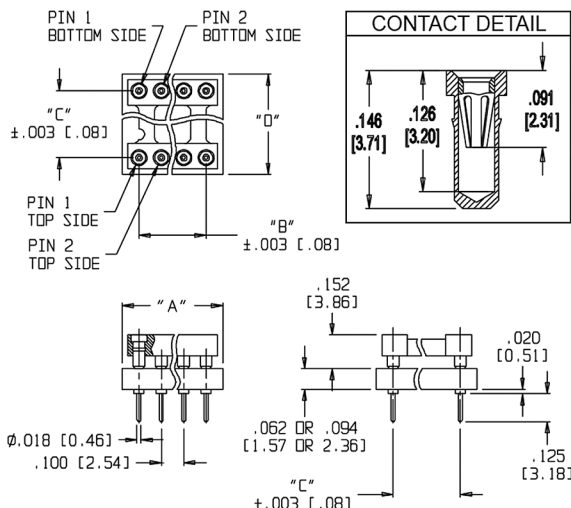

Wire List Example – 8 Pins	
Top Side	Bottom Side
1	8
2	7
3	6
4	5
5	4
6	3
7	2
8	1

Centers "C"	Dim. "D"	Available Sizes
0.300 [7.62]	0.450 [11.43]	8, 14, 16, 18, 20, 24, 28
0.400 [10.16]	0.550 [13.97]	20, 22, 24
0.600 [15.24]	0.750 [19.05]	24, 28, 32, 40, 48



ARIES
ELECTRONICS, INC.

Bristol, PA 19007-6810 USA
TEL (215) 781-9956 • FAX (215) 781-9845
WWW.ARIESELEC.COM • INFO@ARIESELEC.COM

PRINTOUTS OF THIS DOCUMENT MAY BE OUT OF DATE AND SHOULD BE CONSIDERED UNCONTROLLED

18008
Rev. AA

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Aries Electronics:

[1109681-314 100 pcs minimum](#) [1109681-624 100 pcs minimum](#) [1109681-308 100 pcs minimum](#) [1109681-316 100](#)
[pcs minimum](#) [1109681-328 100 pcs minimum](#) [1109681-648 100 pcs minimum](#) [1109681-632 100 pcs minimum](#)
[1109681-628 100 pcs minimum](#) [1109681-324 100 pcs minimum](#) [1109681-318 100 pcs minimum](#) [1109681-320 100 pcs](#)
[minimum](#)