



710-0001-01

Populated RS232 SchmartModule

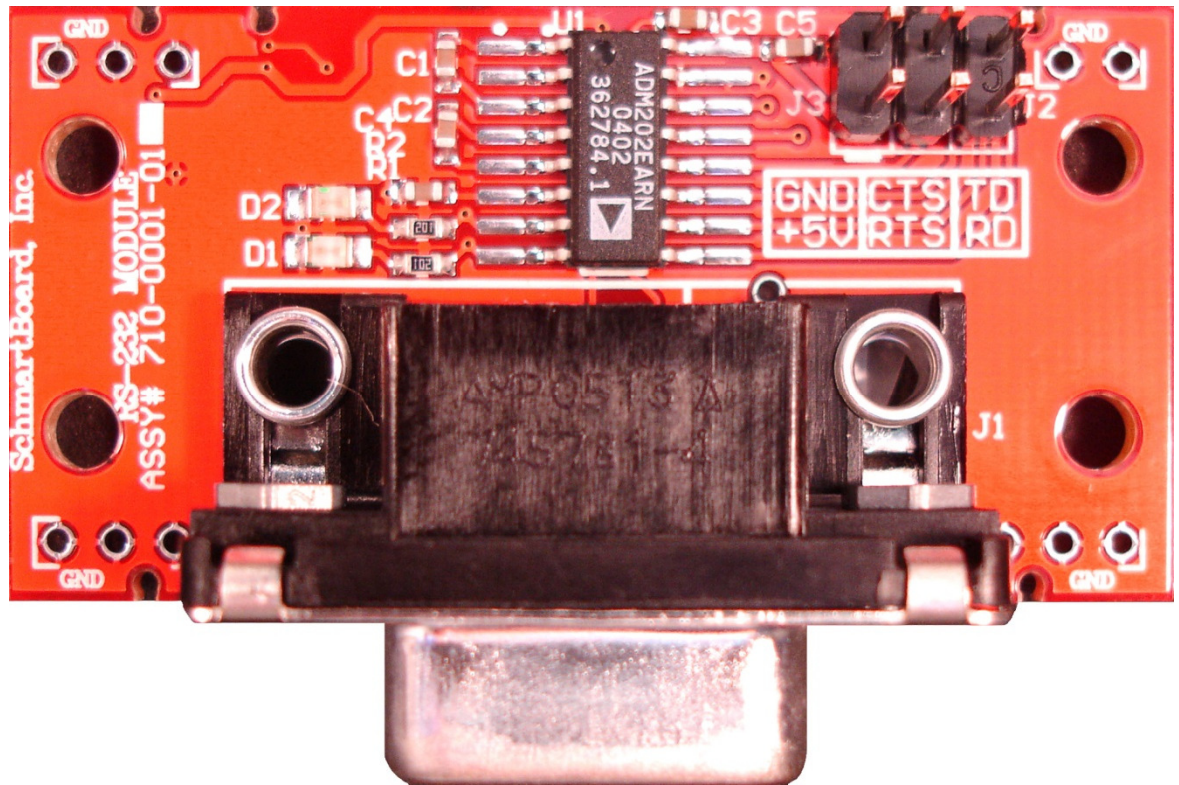

Populated RS232 SchmartModule

Module 2 channels(2 transmit and 2 receive), RS232 and V.28-speeds up to 230Kb. Operates from a single 3.3v or 5v Power source, ESD protected in excess of +/- 15Kv. on all I/O lines, 4 LEDs(2 for transmit, 2 for receive), Preinstalled headers for transceiver lines, Preinstalled headers for +3.3v or +5v and Ground.

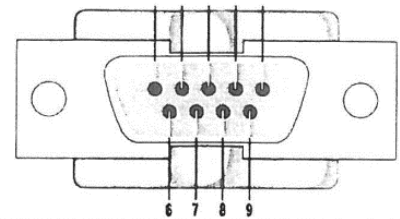

Description	Signal	9-pin DTE	Source DTE or DEC
Carrier Detect	CD	1	from Modem
Receive Data	RD	2	from Modem
Transmit Data	TD	3	from Terminal/Computer
Data Terminal Ready	DTR	4	from Terminal/Computer
Signal Ground	SG	5	from Modem
Data Set Ready	DSR	6	from Modem
Request to Send	RTS	7	from Terminal/Computer
Clear to Send	CTS	8	from Modem
Ring Indicator	RI	9	from Modem

Schmartboard SchmartModule Family



Schmartboard, Inc.
37423 Fremont Blvd.
Fremont, CA 94536

510-744-9900(P)
510-744-9909(F)
<http://www.schmartboard.com>
<http://www.facebook.com/Schmartboard>
<http://www.twitter.com/Schmartboard>

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[SchmartBoard:](#)

[710-0001-01](#)