


920-0012-01 - Qty. Ten 0.1" Spacing 40-Dual Row Headers

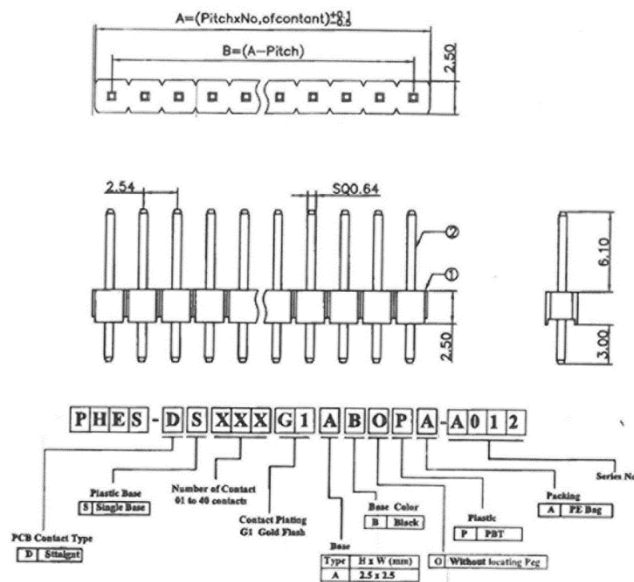

LTR	Part Name	Material	Description
1	Housing	PBT UL94V-0	200° C for 20 Seconds. Initial : 1000M Ohms Min. After Test : 500M Ohms Min.
2	Contact	Brass C2600	Current Rating : 3.0A Initial : 20m Ohms Max. After Test : 40m Ohms Max.


Normal Force : 800 Grams Average.
Temperature Rating : -40° C ~ +125° C.
Dielectric Withstanding Voltage : 1000V AC/Min



P.C.B LAYOUT

L=11.6 mm

RoHS compliant

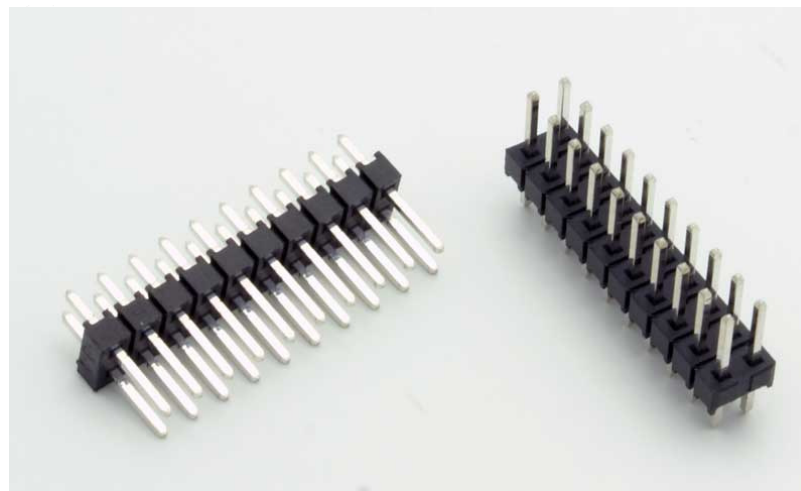

Qty. Ten 0.1" Spacing 40-Dual Row Headers

Breakable for use in whatever quantity you need from 1 to 40; 11.5mm long, .1" spacing, perfect for use with most Schmartboards and breadboards; Schmartboard headers are always immersed in gold to assure the best connection and to avoid oxidation.

Schmartboard Accessory Family



Schmartboard, Inc.
37423 Fremont Blvd.
Fremont, CA 94536

510-744-9900(P)
510-744-9909(F)
<http://www.schmartboard.com>
<http://www.facebook.com/Schmartboard>
<http://www.twitter.com/Schmartboard>

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

SchmartBoard:

920-0012-01