


Product data sheet

Characteristics

AK2GD3750

Cable duct - 50 x 37.5 mm - without cover - grey

Product availability: Non-Stock - Not normally stocked in distribution facility

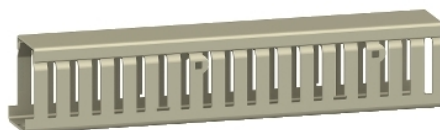

Main

Product or component type	Cable duct
Accessory / separate part category	Cabling accessories
Range compatibility	Spacial CRN Spacial S3D Thalassa PLA Thalassa PLS Thalassa PLM
Device composition	Without cover
Quantity per set	Set of 8

Complementary

Colour	Grey RAL 7030
Fixing mode	Clip-on support By screws
Material	PVC (polyvinyl chloride)
Height	1.97 in (50 mm)
Length	78.74 in (2000 mm)
Width	1.48 in (37.5 mm)
Product weight	1.15 lb(US) (0.52 kg)
Total number of wires	110

Environment

Ambient air temperature for operation	23...140 °F (-5...60 °C)
Flame retardance	VO conforming to UL 94
Fire resistance	1760 °F (960 °C) conforming to IEC 60695-2-1/1
Standards	DIN 43659 VDE 0660 VDE 0506

Ordering and shipping details

Category	22622 - PANEL BUS_(OLD STYLE)
Discount Schedule	I
GTIN	003389110570373
Nbr. of units in pkg.	8
Package weight(Lbs)	0.13
Returnability	N
Country of origin	FR

Offer Sustainability

California proposition 65	WARNING: Cancer and Reproductive Harm - www.P65Warnings.ca.gov
---------------------------	--

Contractual warranty

Warranty period	18 months
-----------------	-----------

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Schneider Electric:](#)

[AK2GD3750](#)