


## Product data sheet

### Characteristics

## DF2FA40

NFC cartridge fuses, TeSys GS, cylindrical, 22mm x 58mm, fuse type aM, 690VAC, 40A, without striker

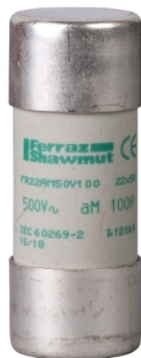

### Main

Range of Product	TeSys fuse-disconnector
Product or Component Type	Cartridge fuse
Device short name	DF2
[Ue] rated operational voltage	690 V AC
Fuse size	22 x 58 mm
Fuse type	NFC
Quantity per Set	Set of 10

### Complementary

Line Rated Current	40 A 690 V
Fuse curve	AM
Net Weight	0.10 lb(US) (0.045 kg)

### Ordering and shipping details

Category	22621-IEC PANEL ACCESSORIES
Discount Schedule	I
GTIN	3389110502787
Nbr. of units in pkg.	1
Package weight(Lbs)	1.73 oz (49.0 g)
Returnability	No
Country of origin	TN

### Packing Units

Unit Type of Package 1	PCE
Package 1 Height	0.94 in (2.4 cm)
Package 1 width	4.65 in (11.8 cm)
Package 1 Length	4.72 in (12 cm)
Unit Type of Package 2	BB1
Number of Units in Package 2	10
Package 2 Weight	17.43 oz (494.0 g)
Package 2 Height	0.94 in (2.4 cm)
Package 2 width	4.65 in (11.8 cm)
Package 2 Length	4.72 in (12 cm)
Unit Type of Package 3	S01
Number of Units in Package 3	120
Package 3 Weight	14.59 lb(US) (6.62 kg)
Package 3 Height	5.91 in (15 cm)
Package 3 width	5.91 in (15 cm)
Package 3 Length	15.75 in (40 cm)

## Offer Sustainability

Sustainable offer status	Green Premium product
California proposition 65	WARNING: Cancer and Reproductive Harm - <a href="http://www.P65Warnings.ca.gov">www.P65Warnings.ca.gov</a>
REACH Regulation	<a href="#">REACH Declaration</a>
REACH free of SVHC	Yes
EU RoHS Directive	Compliant <a href="#">EU RoHS Declaration</a>
Toxic heavy metal free	Yes
Mercury free	Yes
RoHS exemption information	<a href="#">Yes</a>
China RoHS Regulation	<a href="#">China RoHS Declaration</a>
Environmental Disclosure	<a href="#">Product Environmental Profile</a>
PVC free	Yes

## Contractual warranty

Warranty	18 months
----------	-----------

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Schneider Electric:](#)

[DF2FA40](#)