


# GS1AM110

Auxiliary contacts, TeSys GS, 1 NO, early break, front mounting, for GS2 with front/side handle

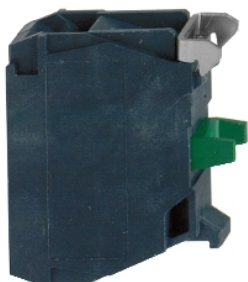

## Main

Range of Product	TeSys
Device short name	GS1AM
Product or Component Type	Auxiliary contact
Contact application	O, I and test position signalling
Range compatibility	TeSys GS fuse-switch disconnecter FuPacT GS fuse-switch disconnecter
Contacts type and composition	1 NO
Contact operation	Early-break
[I <sub>th</sub> ] conventional free air thermal current	10 A 104 °F (40 °C)
[I <sub>e</sub> ] rated operational current	6 A 120 V AC-15 3 A 240 V AC-15 1.8 A 400 V AC-15 1.5 A 480 V AC-15 2.8 A 24 V DC-13 1.4 A 48 V DC-13 0.55 A 125 V DC-13 0.27 A 250 V DC-13 0.15 A 400 V DC-13

## Complementary

Mechanical durability	5 Mcycles
Electrical durability	1 Mcycles AC-15
Switch rated current	30 A 32 A 50 A 60 A 63 A 100 A 125 A 160 A 200 A 250 A 315 A 400 A 600 A 630 A 800 A 1250 A
Fuse type	NFC DIN BS CC J
Type of operating handle	External frontal External right side External left side
Mounting Location	Front face
Net Weight	0.03 lb(US) (0.015 kg)

The information provided in this documentation contains general descriptions and/or technical characteristics of the performance of the products contained herein. This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications. It is the duty of any such user or integrator to perform the appropriate and complete risk analysis, evaluation and testing of the products with respect to the relevant specific application or use thereof. Neither Schneider Electric Industries SAS nor any of its affiliates or subsidiaries shall be responsible or liable for misuse of the information contained herein.

## Ordering and shipping details

Category	22640-IEC DISCONNECT-GS1,LK3
Discount Schedule	I11
GTIN	3389110181760
Nbr. of units in pkg.	1
Package weight(Lbs)	0.42 oz (12.0 g)
Returnability	Yes
Country of origin	FR

## Packing Units

Unit Type of Package 1	PCE
Package 1 Height	0.79 in (2 cm)
Package 1 width	3.15 in (8 cm)
Package 1 Length	3.54 in (9 cm)
Unit Type of Package 2	S01
Number of Units in Package 2	40
Package 2 Weight	25.01 oz (709.0 g)
Package 2 Height	5.91 in (15 cm)
Package 2 width	5.91 in (15 cm)
Package 2 Length	15.75 in (40 cm)

## Offer Sustainability

Sustainable offer status	Green Premium product
California proposition 65	WARNING: This product can expose you to chemicals including: Styrene, which is known to the State of California to cause cancer. For more information go to <a href="http://www.P65Warnings.ca.gov">www.P65Warnings.ca.gov</a>
REACH Regulation	<a href="#">REACH Declaration</a>
REACH free of SVHC	Yes
EU RoHS Directive	Compliant <a href="#">EU RoHS Declaration</a>
Toxic heavy metal free	Yes
Mercury free	Yes
RoHS exemption information	<a href="#">Yes</a>
China RoHS Regulation	<a href="#">China RoHS Declaration</a>
Environmental Disclosure	<a href="#">Product Environmental Profile</a>
Circularity Profile	<a href="#">End Of Life Information</a>

## Contractual warranty

Warranty	18 months
----------	-----------

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Schneider Electric:](#)

[GS1AM110](#)