


Product data sheet

Characteristics

70-378-1

Socket, SE Relays, 5A, 14 pins, solder terminals, separate contact, for 782H / 792 relays

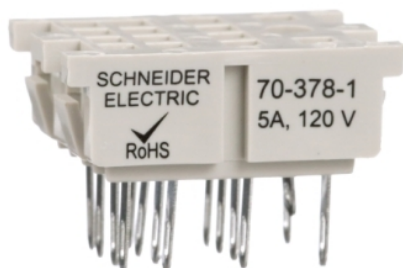

Main

Product Range	Harmony Electromechanical Relays
Product Type	Socket
Product Compatibility	Relay 792XDX Relay 782XDXH
Number of Terminals	14
Switch Function	4PDT
Contact Composition	4 C/O

Complementary

Rated Current	5 A
[Ue] rated operational voltage	120 V
Contact Terminal Arrangement	Mixed
Connections Terminals	Output solder terminalsolid Output solder terminalstranded
Tightening Torque	Chassis 1 N.m, AWG 18, copper
Fixing Mode	By screw, M3.5 chassis
Product Weight	0.22 oz (6.2 g)
Width	0.86 in (21.8 mm)
Depth	2.24 in (57 mm)

Environment

Ambient Air Temperature for Storage	-40...221 °F (-40...105 °C)
Ambient Air Temperature for Operation	-40...131 °F (-40...55 °C)
Flame Retardance	UL94-V0
Product Certifications	UL CSA CE

Ordering and shipping details

GTIN	3606480277894
------	---------------


Offer Sustainability

California proposition 65	WARNING: This product can expose you to chemicals including: Nickel compounds, which is known to the State of California to cause cancer, and Di-isodecyl phthalate (DIDP), which is known to the State of California to cause birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov
REACH Regulation	REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes

RoHS exemption information	 Yes
China RoHS Regulation	 China RoHS Declaration
WEEE	The product must be disposed on European Union markets following specific waste collection and never end up in rubbish bins.

- (1) : Metal hold-down clip
(2) : Recommended chassis cutout top view

Wiring Diagram

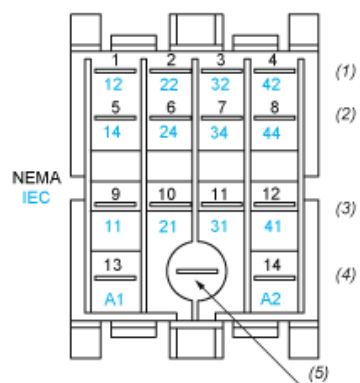

- (1) : N.C.
- (2) : N.O.
- (3) : COM
- (4) : Input
- (5) : Ground lug

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Schneider Electric:](#)

[70-378-1](#)