

RSZE08P

Harmony, Push-in socket with clamp, for RSB1A/RSB2A relays, 10 A, push-in terminals, separate contact



Main

Range of Product	Harmony Electromechanical Relays
Product or Component Type	Socket
Contact terminal arrangement	Separate
Product compatibility	Plug-in relay RSB 2 C/O
Shape of pin	Flat
Device short name	RSZ
Sale per indivisible quantity	10

Complementary

[Ith] conventional free air thermal current	10 A
[Ue] rated operational voltage	250 V IEC 300 V UL
[Uimp] rated impulse withstand voltage	4 kV
[Ui] rated insulation voltage	250 V
Fixing mode	Clip-on 35 mm symmetrical DIN rail)
Marking	CE
Length	3.86 in (98 mm)
Width	0.63 in (16 mm)
Height	2.36 in (60 mm)
Net Weight	0.09 lb(US) (0.042 kg)

Environment

Overvoltage category	III
Pollution degree	3
Connections - terminals	Spring clamp terminals (push 'n stay), 1 x 0.5...1 x 1.5 mm ² AWG 20...AWG 16) flexible with cable end Spring clamp terminals (push 'n stay), 1 x 0.5...1 x 1.5 mm ² AWG 20...AWG 16) solid without cable end
Standards	IEC 61984
Product Certifications	CSA UL EAC
Ambient Air Temperature for Storage	-40...185 °F (-40...85 °C)
Ambient air temperature for operation	-40...185 °F (-40...85 °C)
IP degree of protection	IP20
Dielectric strength	2500 V

Ordering and shipping details

Category	21128 - ZELIO ICE CUBE RELAY ACCESSORIES
Discount Schedule	CP2
GTIN	3606481465740
Nbr. of units in pkg.	1
Package weight(Lbs)	1.41 oz (40 g)
Returnability	Yes

Packing Units

Unit Type of Package 1	PCE
Package 1 Height	0.59 in (1.5 cm)
Package 1 width	2.36 in (6 cm)
Package 1 Length	3.94 in (10 cm)
Unit Type of Package 2	BB1
Number of Units in Package 2	10
Package 2 Weight	15.80 oz (448 g)
Package 2 Height	2.95 in (7.5 cm)
Package 2 width	4.13 in (10.5 cm)
Package 2 Length	6.50 in (16.5 cm)
Unit Type of Package 3	S03
Number of Units in Package 3	160
Package 3 Weight	17.00 lb(US) (7.71 kg)
Package 3 Height	11.81 in (30 cm)
Package 3 width	11.81 in (30 cm)
Package 3 Length	15.75 in (40 cm)


Offer Sustainability

Sustainable offer status	Green Premium product
California proposition 65	WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov
REACH Regulation	REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS Declaration
Environmental Disclosure	Product Environmental Profile
WEEE	The product must be disposed on European Union markets following specific waste collection and never end up in rubbish bins.


Contractual warranty

Warranty	18 months
----------	-----------


Dimensions

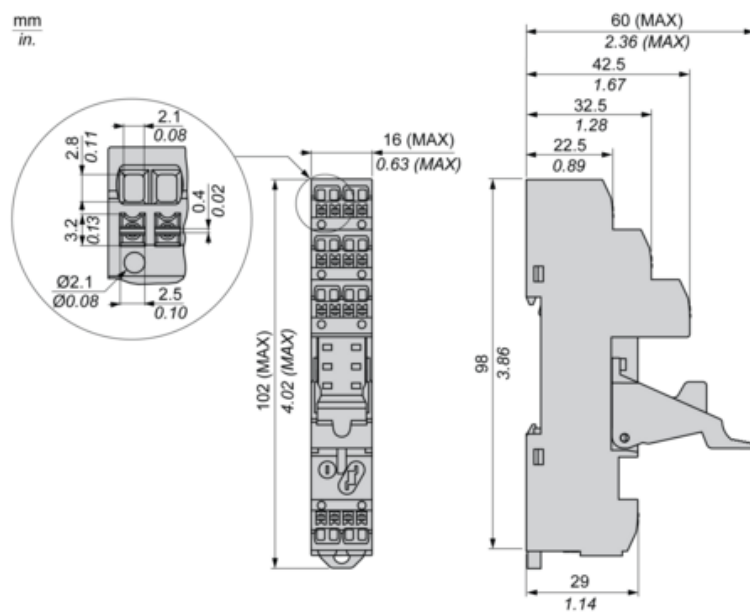

Wiring

 

Wiring

 


NOTE: If RSZE08P socket terminals are linked, relay RSB1A160** can be used up to 16A.

Installation



Installation


Push In (Insert Cable)

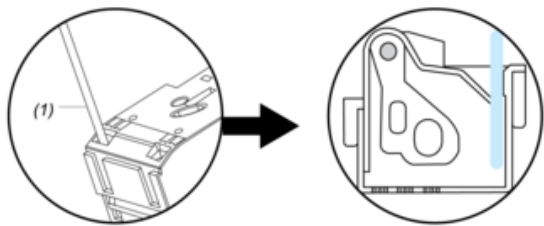

(1) : Insert Wire

Uninstallation

Pull Out (Remove Cable)

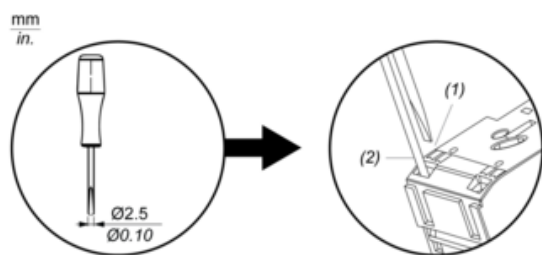

(1) : Press

(2) : Pull Wire

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Schneider Electric:](#)

[RSZE08P](#)