

Product availability: Non-Stock - Not normally stocked in distribution facility



Main

Range of product	Modicon M171
Product or component type	Display module
Display colour	Monochrome
Supply	External source

Complementary

Display type	7 segments LED + decimal point
Number of key	8
Color	Grey
[Us] rated supply voltage	12 V DC
Power consumption in W	5 W 0 W
Marking	CE
Local signalling	LED
Product compatibility	Logic controller M171 optimized
Height	2.91 in (74 mm)
Width	1.26 in (32 mm)
Depth	1.18 in (30 mm)
Product weight	0.09 lb(US) (0.042 kg)


Environment

Standards	RoHS compliant
Product certifications	CURus REACH
IP degree of protection	IP20

Ordering and shipping details


Category	22537 - M171 / M172 HVAC CONTROLLERS
Discount Schedule	PC12
GTIN	003606480752643
Nbr. of units in pkg.	1
Package weight(Lbs)	0.38
Returnability	N
Country of origin	IT

Offer Sustainability


RoHS (date code: YYWW)	Compliant - since 1429 - Schneider Electric declaration of conformity  Schneider Electric declaration of conformity
REACH	Reference not containing SVHC above the threshold
California proposition 65	WARNING: This product can expose you to chemicals including:
- - - - - Substance 1	Lead and lead compounds which is known to the State of California to cause cancer and birth defects or other reproductive harm.
- - - - - More information	For more information go to www.p65warnings.ca.gov

Dimensions


mm
in.

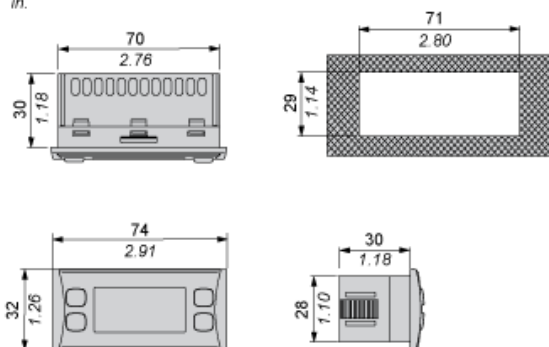

Mounting on Panel with the Special Brackets Provided

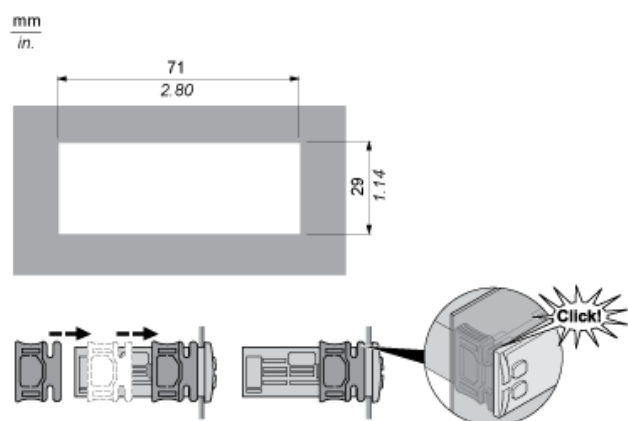

Power Supply

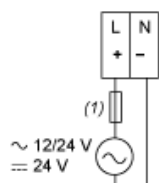

(1) Type T fuse (Controller: 1.25 A , Expansion: 1 A)

Wiring Diagram



BK : Black
BU : Blue
RD : Red

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Schneider Electric:](#)

[TM171DLED](#)