


# Product data sheet

## Characteristics

# PVR

## REPLACEABLE, RACKMOUNT, 1U, SINGLE LINE, CableTV SURGE PROTECTION MODULE

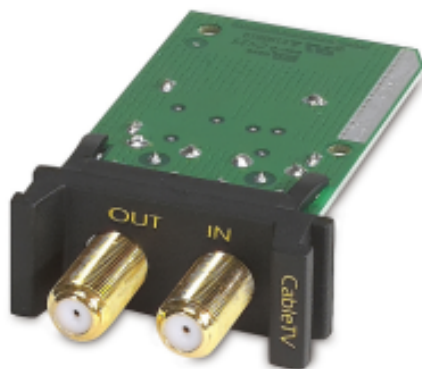

### Overview

Lead time	Usually in Stock
-----------	------------------

### Physical

Color	Black
Depth	2.72 In (6.9 cm)
Height	1.73 In (4.4 cm)
Product Weight	0.13 Lb(US) (0.06 kg)
Width	0.75 In (1.9 cm)

### Output

Number of power socket outlets	1
--------------------------------	---

### Conformance

Product Certifications	UL Recognized
------------------------	---------------

### Environmental

Ambient Air Temperature for Operation	5...113 °F (-15...45 °C)
Operating altitude	0...10000 ft
Relative Humidity	0...95 %
Ambient Air Temperature for Storage	5...113 °F (-15...45 °C)
Storage altitude	0...10000 Ft (0.00...3048.00 m)
Storage Relative Humidity	0...95 %

### Surge Protection and Filtering

Data line protection	Cable modem/video protection Co-axial Video / Cable protection
Data Lines Protected (multi-line only)	1
NM Surge Response Time (ns)	1 ns common mode
Peak current	0.5 KA common mode 0.2 KA normal mode

### Ordering and shipping details

GTIN	00731304217190
Package weight(Lbs)	0.62 Lb(US) (0.28 kg)

### Packing Units

Package 1 Height	3.90 In (9.9 cm)
Package 1 width	1.30 In (3.3 cm)
Package 1 Length	3.74 In (9.5 cm)
SCC14	30731304217191
Number of Units in Package 2	96
Package 2 Height	8.125 In (206.38 mm)
Package 2 width	16.25 In (412.75 mm)
Package 2 Length	25.125 In (638.18 mm)

### Contractual warranty

Warranty	Lifetime
----------	----------

Product Life Status : <b>Commercialised</b>
---

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Schneider Electric:](#)

[PVR](#)