


PVR

REPLACEABLE, RACKMOUNT, 1U, SINGLE LINE, CableTV SURGE PROTECTION MODULE

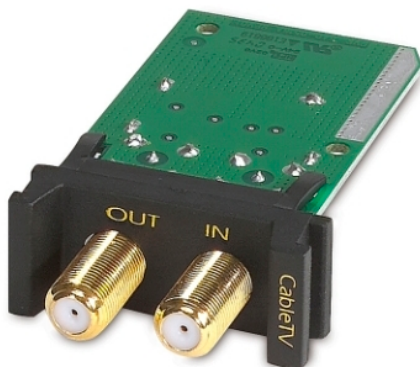

Overview

Lead time	Usually in Stock
-----------	------------------

Physical

Color	Black
Depth	2.72 in (6.9 cm)
Height	1.73 in (4.4 cm)
Product Weight	0.13 lb(US) (0.06 kg)
Width	0.75 in (1.9 cm)

Output

Number of power socket outlets	1
--------------------------------	---

Conformance

Product Certifications	UL Recognized
------------------------	---------------

Environmental

Ambient Air Temperature for Operation	5...113 °F (-15...45 °C)
Operating altitude	0...10000 ft
Relative Humidity	0...95 %
Ambient Air Temperature for Storage	5...113 °F (-15...45 °C)
Storage altitude	0...10000 ft (0.00...3048.00 m)
Storage Relative Humidity	0...95 %

Surge Protection and Filtering

Data line protection	Cable modem/video protection Co-axial Video / Cable protection
Data Lines Protected (multi-line only)	1
NM Surge Response Time (ns)	1 ns common mode
Peak current	0.5 kA common mode 0.2 kA normal mode

Ordering and shipping details

GTIN	00731304217190
Package weight(Lbs)	0.62 lb(US) (0.28 kg)

Packing Units

Package 1 Height	3.90 in (9.9 cm)
Package 1 width	1.30 in (3.3 cm)
Package 1 Length	3.74 in (9.5 cm)
SCC14	30731304217191
Number of Units in Package 2	96
Package 2 Height	8.125 in (206.38 mm)
Package 2 width	16.25 in (412.75 mm)
Package 2 Length	25.125 in (638.18 mm)

Contractual warranty

Warranty	Lifetime
----------	----------

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Schneider Electric:](#)

[PVR](#)