


Product data sheet

Specifications

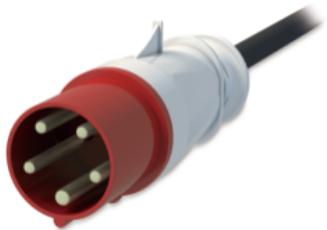

Rack PDU 2G, Metered, ZeroU, 17.3kW, 240V, (30) C13 & (12) C19

AP8887

Overview

Presentation	APC Metered Rack Power Distribution Units (PDUs) provide active metering to enable energy optimization and circuit protection. User-defined alarm thresholds mitigate risk with real-time local and remote alerts to warn of potential circuit overloads. Metered Rack PDUs provide power utilization data to allow Data Center Managers to make informed decisions on load balancing and right sizing IT environments to lower total cost of ownership. Metered Rack PDUs include real power monitoring, a temperature/humidity sensor port, locking IEC receptacles, and ultra low profile circuit breakers. Users can access and configure Metered Rack PDUs through secure Web, SNMP, or Telnet Interfaces which are complimented by APC Centralized Management platforms using InfraStruxure Central, Operations, Capacity, and Energy Efficiency.
--------------	---

Lead time	Usually in Stock
-----------	------------------

Main

Main Output Voltage	240 V
Main Input Voltage	3 phase
Plug standard	IEC 60309 30 A 3P+N+E
Number of rack unit	0U
Cable length	6 ft (1.83 m)
Number of cables	1

General

Provided Equipment	Installation guide Rack Mounting brackets Serial configuration cable Safety guide
--------------------	--

Physical

Color	Black
Depth	2.01 in (5.1 cm)
Height	72.01 in (182.9 cm)
Net Weight	21.16 lb(US) (9.6 kg)
Width	2.20 in (5.6 cm)

Input

Line Rated Current	24 A
Max line current	30 A
Input current limits	30 A

Load Capacity	17300 VA
Input Frequency	50/60 Hz

Output

Number of power socket outlets	30 IEC 60320 C13 12 IEC 60320 C19
--------------------------------	--------------------------------------

Conformance

Product Certifications	cUL Listed UL Listed VCCI Class A
Standards	EN 55022 Class A EN 55024 EN 61000-3-2 EN 61000-3-3 FCC Part 15 class A ICES-003

Environmental

Ambient air temperature for operation	23...140 °F (-5...60 °C)
Relative Humidity	5...95 %
Operating altitude	0...10000 ft
Ambient Air Temperature for Storage	-13...149 °F (-25...65 °C)
Storage Relative Humidity	5...95 %
Storage altitude	0...50000 ft (0.00...15240.00 m)

Ordering and shipping details

GTIN	00731304292432
Package weight(Lbs)	29.98 lb(US) (13.6 kg)

Packing Units

Package 1 Height	84.61 in (214.9 cm)
Package 1 width	8.70 in (22.1 cm)
Package 1 Length	4.41 in (11.2 cm)

Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	REACH Declaration
EU RoHS Directive	Compliant EU RoHS Declaration
Lead free	Yes
Mercury free	Yes
RoHS exemption information	Yes
Environmental Disclosure	Product Environmental Profile
Circularity Profile	End of Life Information
Optimized Energy Efficiency	Energy efficient product
Take-back	Take-back program available

Contractual warranty

Warranty	2 years repair or replace
----------	---------------------------

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Schneider Electric:](#)

[AP8887](#)