


LK4JUKR1

TeSys LK disconnect switch kit, disconnect switch, 3 P, 100 A, shaft, guide cone, red handle, NEMA 1, 3R and 12

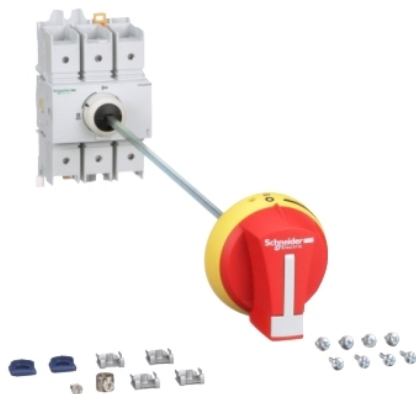

Main

Range	TeSys
Product or component type	Disconnect Switch
Disconnecter device type	Non-fusible disconnect switch
Suitability for isolation	Yes
Handle colour	Red
Handle front plate colour	Yellow

Complementary

Poles description	3P
Network type	AC
Network frequency	50/60 Hz
[Ie] rated operational current	100 A600 V AC UL 100 A600 V AC CSA 100 A400 V AC AC-22A IEC 100 A400 V AC AC-23A IEC 100 A690 V AC AC-22A IEC 100 A690 V AC AC-23A IEC
[Ue] rated operational voltage	600 V AC 50/60 Hz
Rated power in W	51 KW 400 V 63 KW 500 V 90 kW 690 V
Rated power in hp	20 Hp 240 V 53 A AC 50 Hp 480 V 64 A AC 50 hp 600 V 51 A AC
[Icw] rated short-time withstand current	17.6 kA
Mechanical durability	10000 cycles
Electrical durability	6000 cycles
Connections - terminals	Lugs-ring terminals 1 0.01 in ² (4 mm ²)
Width	3.13 in (79.5 mm)

Environment

NEMA degree of protection	NEMA 1/12/3R
Standards	UL98 CSA C22.2 No 4 IEC 60947-3
Product certifications	UL CSA
Height	4.92 in (125 mm)
Depth	2.52 in (64 mm)

The information provided in this documentation contains general descriptions and/or technical characteristics of the performance of the products contained herein. This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications. It is the duty of any such user or integrator to perform the appropriate and complete risk analysis, evaluation and testing of the products with respect to the relevant specific application or use thereof. Neither Schneider Electric Industries SAS nor any of its affiliates or subsidiaries shall be responsible or liable for misuse of the information contained herein.

Ordering and shipping details

Category	22640 - IEC DISCONNECT-GS1,LK3
Discount Schedule	I11
GTIN	00785901806677
Nbr. of units in pkg.	1
Package weight(Lbs)	2.47 lb(US) (1.12 kg)
Returnability	Yes
Country of origin	US

Packing Units

Package 1 Height	3.50 in (8.890 cm)
Package 1 width	5.80 in (14.732 cm)
Package 1 Length	17.80 in (45.212 cm)

Offer Sustainability

California proposition 65	WARNING: This product can expose you to chemicals including: Antimony oxide & Antimony trioxide, which is known to the State of California to cause cancer. For more information go to www.P65Warnings.ca.gov
REACH free of SVHC	Yes
EU RoHS Directive	Compliant EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS Declaration
WEEE	The product must be disposed on European Union markets following specific waste collection and never end up in rubbish bins.

Contractual warranty

Warranty	18 months
----------	-----------

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Schneider Electric:](#)

[LK4JUKR1](#)