


Product data sheet

Characteristics

DF3FA100

NFC cartridge fuses, Tesys GS, cylindrical, 22 mm x 58 mm, fuse type aM, 500 VAC, 100 A, with striker

Product availability: Non-Stock - Not normally stocked in distribution facility

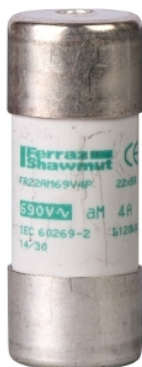

Main

Range of product	TeSys fuse-disconnector
Product or component type	Cartridge fuse
Device short name	DF3
System Voltage	500 V AC
Fuse size	22 x 58 mm
Fuse type	NFC
Quantity per set	Set of 10


Complementary

[In] rated current	100 A 500 V
Fuse curve	AM
Local signalling	Striker
Product weight	0.1 lb(US) (0.045 kg)

Ordering and shipping details

Category	22621 - IEC PANEL ACCESSORIES
Discount Schedule	I
GTIN	003389110504187
Nbr. of units in pkg.	10
Package weight(Lbs)	0.01
Returnability	N
Country of origin	TN

Offer Sustainability

RoHS (date code: YYWW)	Compliant - since 9848 - Schneider Electric declaration of conformity  Schneider Electric declaration of conformity
REACH	Reference not containing SVHC above the threshold

Contractual warranty

Warranty period	18 months
-----------------	-----------

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Schneider Electric:](#)

[DF3FA100](#)