

XVR12B05S

Harmony XVR, Rotating beacon, Ø120, orange, with buzzer 50...90 dB, 24 V AC/DC



Main

Range of Product	Harmony XVR
Product or Component Type	Prewired rotating mirror beacon
Sound signalling	Buzzer
Device short name	XVR
Mounting diameter	4.72 in (120 mm)
IP degree of protection	IP23 IEC 60529
[Us] rated supply voltage	24 V AC/DC
Light source	High luminosity LED, orange
Noise level	50...90 dB continuous or intermittent tone)1 m

Complementary

Material	ABS (acrylonitrile butadiene-styrene) body part AS globe
CAD overall width	4.72 in (120 mm)
CAD overall depth	4.72 in (120 mm)
Net Weight	1.10 lb(US) (0.5 kg)
Marking	CE
Product mounting	By 3 M5 screws
Supply voltage limits	19...30 V DC 21.6...26.4 V AC
[Uimp] rated impulse withstand voltage	0.8 kV
Current Consumption	196 mA
Flashing frequency	2.3 Hz
Clamping Connection Capacity	0.83 mm ²
AWG Gauge	AWG 18
Cable length	15.75 in (400 mm)

Environment

Standards	EN 61000-6-4 EN 61000-6-2
Protective treatment	TC
Ambient Air Temperature for Storage	-31...158 °F (-35...70 °C)
Ambient Air Temperature for Operation	14...122 °F (-10...50 °C)
Electrical shock protection class	Class II IEC 61140

Ordering and shipping details

Category	22617-XVC TOWER LIGHTS
Discount Schedule	XV
GTIN	3606480033247
Nbr. of units in pkg.	1
Package weight(Lbs)	22.50 oz (638.0 g)
Returnability	No
Country of origin	JP

Packing Units

Unit Type of Package 1	PCE
Package 1 Height	7.68 in (19.5 cm)
Package 1 width	5.51 in (14 cm)
Package 1 Length	5.51 in (14 cm)

Offer Sustainability


Sustainable offer status	Green Premium product
California proposition 65	WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov
REACH Regulation	REACH Declaration
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS Declaration
Environmental Disclosure	Product Environmental Profile
Circularity Profile	End Of Life Information

Contractual warranty


Warranty	18 months
----------	-----------

Rotating Mirror Beacon

Dimensions

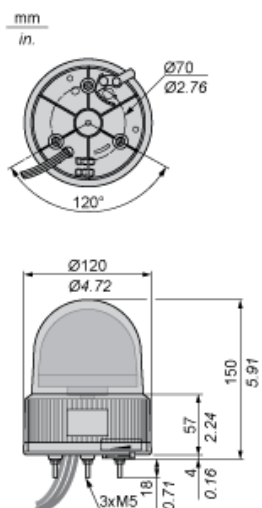

Panel Cut-out

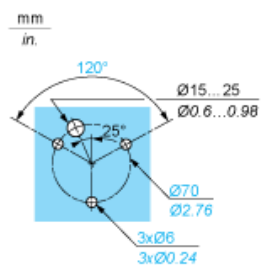

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Schneider Electric:](#)

[XVR12B05S](#)