

## Magnecraft

191 Waukegan Rd, Ste 206  
Northfield, IL 60093-2743

**Phone:** (847)441-2526


**Fax:** (847)441-2522

**Email:** relays@magnecraft.com

### Item # W199AX-9, 199 Open Style Power Relays / DPST-NO, 40 Amp Rating (AC)

**QUOTE**

### 199 Open Style Power Relays / DPST-NO, 40 Amp Rating (AC)

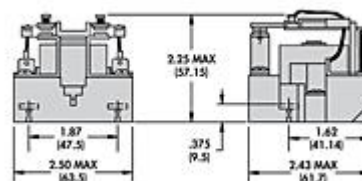

[SPECIFICATIONS](#) · [CONTACT CHARACTERISTICS](#) · [COIL CHARACTERISTICS](#) · [PERFORMANCE CHARACTERISTICS](#) · [ENVIRONMENT](#) · [PRODUCT CERTIFICATIONS](#)

### SPECIFICATIONS

Control	AC
Nominal Input Voltage	120 VAC 50/60 Hz
Coil Resistance	290 Ohm
Cover Style	Open Style
Weight	227 to 312 G

### CONTACT CHARACTERISTICS

Contact Rating	40 A
Contact Configuration	DPST-NO
Contact Materials	Silver Alloy
Maximum Switching Voltage	600 V

Switching Current at Voltage (AC, Resistive)	40 A at 277 V 50 / 60 Hz
Switching Current at Voltage (DC, Resistive)	40 A at 28 VDC
Switching Current at Voltage (Pilot Duty)	A600
Minimum Switching Requirement	1 A at 12 VAC

## COIL CHARACTERISTICS

Operating Range - % of Nominal (AC)	85 to 110 %
Operating Range - % of Nominal (DC)	80 to 110 %
Average Consumption (AC)	10 VA
Average Consumption (DC)	4 W
Drop-out Voltage Threshold (DC)	10 %
Drop-out Voltage Threshold (AC)	10 %

## PERFORMANCE CHARACTERISTICS

Electrical Life (UL508), Operations at Rated Current (Resistive)	100000
Mechanical Life, Unpowered	1000000
Operating Time (Response Time)	30 ms

## ENVIRONMENT

Ambient Air Temperature around the Device - Storage	-40 to +85 °C
Ambient Air Temperature around the Device - Operation	-40 to +55 °C
Connection	8 AWG 10 mm <sup>2</sup>
Terminal Tightening Torque	7 to 9 in lb 0.8 to 1.0 N·m

## PRODUCT CERTIFICATIONS

Agency Approvals	UL CE CSA
------------------	-----------------

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Schneider Electric:](#)

[W199AX-9](#)