

## Product data sheet

### Characteristics

# XZCC18FCP40B

female, M18, 4-pin, elbowed connector - cable gland Pg 9

Product availability: Non-Stock - Not normally stocked in distribution facility



### Main

Accessory / separate part category	Cabling accessories
Accessory / separate part type	Connector
Electrical connection	Elbowed female connector M18, 4 pins
Collar material	Plastic
Status LED	Without
Cable connection	Screw terminal / wire size $\leq 0 \text{ in}^2$ (1.5 mm <sup>2</sup> ) / clamping capacity 0.2...0.31 in (5...8 mm)

### Complementary

Cable gland type	Pg 9
Cable connector fixing	Screw-on
System Voltage	250 V AC
Line Rated Current	16 A
Enclosure material	Plastic
Insulating resistance	$> 1000 \text{ G}\Omega$
Contact resistance	$\leq 10000 \mu\text{Ohm}$
Product weight	0.08 lb(US) (0.035 kg)

### Environment

IP degree of protection	IP65
Ambient air temperature for operation	-40...185 °F (-40...85 °C)

### Ordering and shipping details

Category	22483 - MACHINE CABLES
Discount Schedule	DS3
GTIN	00785901756415
Nbr. of units in pkg.	1
Package weight(Lbs)	7.0000000000000007E-2
Returnability	N
Country of origin	DE


### Offer Sustainability

RoHS (date code: YYWW)	Compliant - since 0545 - Schneider Electric declaration of conformity <a href="#">Schneider Electric declaration of conformity</a>
California proposition 65	WARNING: This product can expose you to chemicals including:
----- Substance 1	Diisononyl phthalate (DINP), which is known to the State of California to cause cancer, and
----- Substance 2	Di-isodecyl phthalate (DIDP), which is known to the State of California to cause birth defects or other reproductive harm.
----- More information	For more information go to <a href="http://www.p65warnings.ca.gov">www.p65warnings.ca.gov</a>

Contractual warranty

Warranty period	18 months
-----------------	-----------

## Dimensions

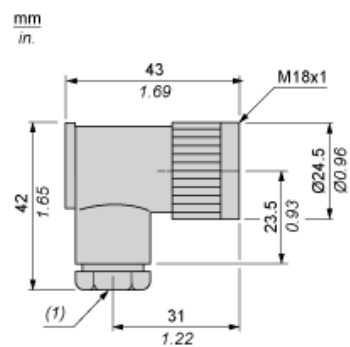


(1) Pg 9 cable gland

---

Connections and Schemes

---

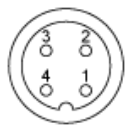

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Schneider Electric:

[XZCC18FCP40B](#)