

Product data sheet

Characteristics

XZCRA151141C2

jumper cable XZ - male straight M12 4-pin -
female straight M12 4-pin - PVC 2m

Product availability: Non-Stock - Not normally stocked in distribution facility



Main

Accessory / separate part category	Cabling accessory
Accessory / separate part type	Jumper cable

Complementary

Jumper cable end 1	M12 male, :4 pins (straight), fixing: screw-on and clip-on
Jumper cable end 2	M12 female, :4 pins (straight), fixing: screw-on and clip-on
Collar material	Metal
Cable composition	4 x 0.34 mm ²
Cable length	6.56 ft (2 m)
Cable outer diameter	0.21 in (5.3 mm)
System Voltage	250 V AC 300 V DC
Line Rated Current	4 A
Insulation resistance	>= 1000 MOhm
Resistance across terminals	<= 5000 mOhm
Product weight	0.23 lb(US) (0.105 kg)

Environment

IP degree of protection	IP69K
Ambient air temperature for operation	-13...185 °F (-25...85 °C) (static)

Ordering and shipping details

Category	22483 - MACHINE CABLES
Discount Schedule	DS3
GTIN	003389119021692
Nbr. of units in pkg.	1
Package weight(Lbs)	0.25
Returnability	N
Country of origin	PL


Offer Sustainability

RoHS (date code: YYWW)	Compliant - since 0601 - Schneider Electric declaration of conformity  Schneider Electric declaration of conformity
California proposition 65	WARNING: This product can expose you to chemicals including:
- - - - - Substance 1	Diisononyl phthalate (DINP), which is known to the State of California to cause cancer, and
- - - - - Substance 2	Di-isodecyl phthalate (DIDP), which is known to the State of California to cause birth defects or other reproductive harm.
- - - - - More information	For more information go to www.p65warnings.ca.gov

Contractual warranty


Warranty period	18 months
-----------------	-----------

Dimensions

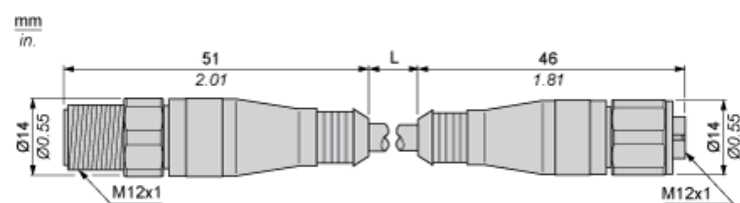

L : Length of cable

Connections and Schemes

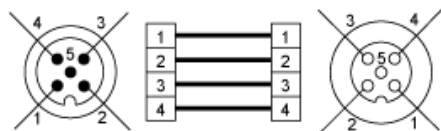

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Schneider Electric:](#)

[XZCRA151141C2](#)