


Product availability: Stock - Normally stocked in distribution facility

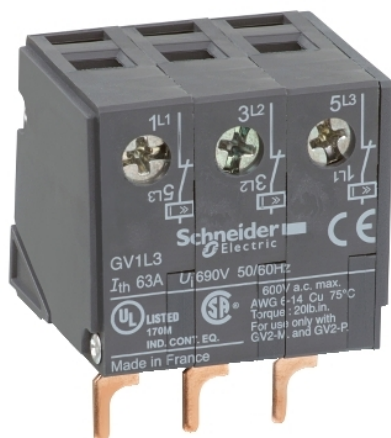

Main

Range	TeSys
Accessory / separate part category	Protection accessory
Product or component type	Current limiting module
Function of module	Increasing the breaking capacity of a circuit breaker
Range compatibility	TeSys TeSys GV2
Product compatibility	GV2ME GV2P GV2L GV2RT
Mounting location	On top of the circuit breaker
[Ie] rated operational current	32 A
[Ith] conventional free air thermal current	63 A conforming to IEC 60947-1
Operating threshold	1500 A
Breaking capacity	<= 100 kA depending on protective device
System Voltage	690 V AC 50/60 Hz
[Ui] rated insulation voltage	690 V AC 50/60 Hz conforming to IEC 60947-1

Complementary

Connections - terminals	Screw clamp terminals 1 1.5...25 mm ² rigid Screw clamp terminals 2 1.5...10 mm ² rigid Screw clamp terminals 1 1.5...25 mm ² flexible without cable end Screw clamp terminals 2 1.5...10 mm ² flexible without cable end Screw clamp terminals 1 1.5...16 mm ² flexible with cable end Screw clamp terminals 2 1.5...4 mm ² flexible with cable end
Tightening torque	19.47 lbf.in (2.2 N.m)
Product weight	0.29 lb(US) (0.13 kg)

Ordering and shipping details

Category	22366 - MAN STR PROTECTORS-GV1/GV3
Discount Schedule	I11
GTIN	00785901209959
Nbr. of units in pkg.	1
Package weight(Lbs)	0.27000000000000002
Returnability	Y
Country of origin	FR

Offer Sustainability


California proposition 65	WARNING: This product can expose you to chemicals including:
- - - - - Substance 1	Antimony oxide & Antimony trioxide, which is known to the State of California to cause cancer.
- - - - - More information	For more information go to www.p65warnings.ca.gov

Contractual warranty

Warranty period	18 months
-----------------	-----------

Current Limiter

 GV1L3



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Schneider Electric:](#)

[GV1L3](#)