

Product data sheet

Characteristics

GV2G05

TeSys GV2, TeSys D & TeSys U - terminal block - 3P - for GV1L3



Product availability: Stock - Normally stocked in distribution facility



Main

Range	Linergy
Product name	FT
Device short name	GV2G
Product or component type	Terminal block
Accessory / separate part category	Connection accessory
Poles description	3P
Range compatibility	TeSys - GV2 TeSys - U TeSys - D TeSys - K

Complementary

[Ie] rated operational current	63 A
Mounting location	Top
IP degree of protection	IP20 according to IEC 60529
[Ui] rated insulation voltage	690 V according to IEC 60947-1
Connections - terminals	Screw clamp terminals 1 cable(s) 1.5...10 mm ² flexible with cable end Screw clamp terminals 1 cable(s) 1.5...16 mm ² flexible without cable end Screw clamp terminals 2 cable(s) 1.5...2 mm ² flexible with cable end Screw clamp terminals 2 cable(s) 2.5...4 mm ² flexible without cable end Screw clamp terminals 1 flexible AWG 4 Screw clamp terminals 1 solid AWG 4 Screw clamp terminals 1 cable(s) 0...0.04 in ² (1.5...25 mm ²) solid Screw clamp terminals 2 cable(s) 0...0.01 in ² (1.5...6 mm ²) solid
Tightening torque	15.04 lbf.in (1.7 N.m) - on screw clamp terminals 19.47 lbf.in (2.2 N.m) - on connector
Product weight	0.25 lb(US) (0.115 kg)

Ordering and shipping details

Category	22367 - MANUAL STR PROTECTOR - GV2
Discount Schedule	I11
GTIN	00785901808350
Nbr. of units in pkg.	1
Package weight(Lbs)	0.27000000000000002
Returnability	Y
Country of origin	RO


Offer Sustainability

Sustainable offer status	Green Premium product
RoHS (date code: YYWW)	Compliant - since 0640 - Schneider Electric declaration of conformity Schneider Electric declaration of conformity
REACH	Reference not containing SVHC above the threshold
Product environmental profile	Available
Product end of life instructions	Need no specific recycling operations

Contractual warranty

Warranty period	18 months
-----------------	-----------

Sets of Busbars GV2G445, GV2G454, GV2G472, with Terminal Block GV2G05

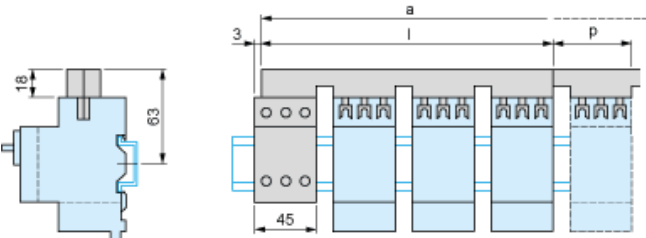

		l	p	
GV2G445 (4 x 45 mm)		179	45	
GV2G454 (4 x 54 mm)		206	54	
GV2G472 (4 x 72 mm)		260	72	

Number of tap-offs	a			
	5	6	7	8
GV2G445	224	269	314	359
GV2G454	260	314	368	422
GV2G472	332	404	476	548

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Schneider Electric:](#)

[GV2G05](#)