

Product data sheet


Characteristics

GV2G445

Lineryg FT - Comb busbar - 63 A - 4 tap-offs - 45 mm pitch



Product availability: Stock - Normally stocked in distribution facility

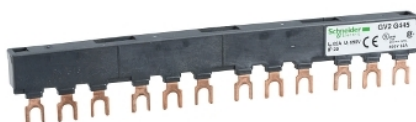

Main

Range	Lineryg
Product name	FT
Device short name	GV2G
Product or component type	Comb busbar
Accessory / separate part category	Connection accessory
Poles description	3P
Range compatibility	TeSys - GV2 TeSys - U TeSys - D TeSys - K
Number of tap-offs	4
[I _{th}] conventional free air thermal current	63 A
Connection pitch	1.77 in (45 mm)

Complementary

Mounting location	On terminal
[Ui] rated insulation voltage	690 V
Length	7.05 in (179 mm)
Product weight	0.17 lb(US) (0.077 kg)

Ordering and shipping details

Category	22367 - MANUAL STR PROTECTOR - GV2
Discount Schedule	I11
GTIN	00785901555889
Nbr. of units in pkg.	1
Package weight(Lbs)	0.17999999999999999
Returnability	Y
Country of origin	RO


Offer Sustainability

Sustainable offer status	Green Premium product
RoHS (date code: YYWW)	Compliant - since 0640 - Schneider Electric declaration of conformity  Schneider Electric declaration of conformity
REACH	Reference not containing SVHC above the threshold
Product environmental profile	Available
Product end of life instructions	Need no specific recycling operations

Contractual warranty

Warranty period	18 months
-----------------	-----------

Sets of Busbars GV2G445, GV2G454, GV2G472, with Terminal Block GV2G05

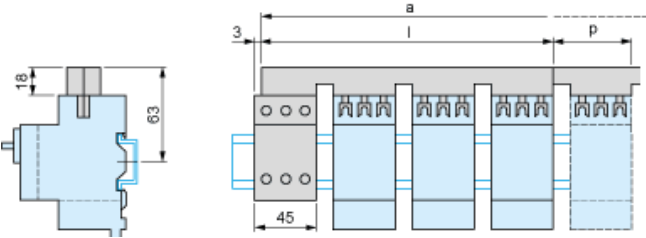

		l	p	
GV2G445 (4 x 45 mm)		179	45	
GV2G454 (4 x 54 mm)		206	54	
GV2G472 (4 x 72 mm)		260	72	

Number of tap-offs	a			
	5	6	7	8
GV2G445	224	269	314	359
GV2G454	260	314	368	422
GV2G472	332	404	476	548

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Schneider Electric:](#)

[GV2G445](#)