




Product availability: Non-Stock - Not normally stocked in distribution facility

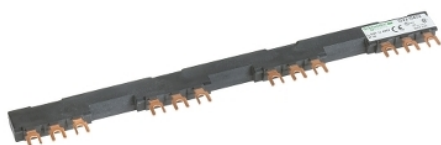

### Main

Range	Linergy
Product name	FT
Device short name	GV2G
Product or component type	Comb busbar
Accessory / separate part category	Connection accessory
Poles description	3P
Range compatibility	TeSys - GV2 TeSys - U TeSys - D TeSys - K
Number of tap-offs	4
[I <sub>th</sub> ] conventional free air thermal current	63 A
Connection pitch	2.83 in (72 mm)

### Complementary

Mounting location	On terminal
[Ui] rated insulation voltage	690 V
Length	10.24 in (260 mm)
Product weight	0.21 lb(US) (0.094 kg)

### Ordering and shipping details

Category	22367 - MANUAL STR PROTECTOR - GV2
Discount Schedule	I11
GTIN	00785901490111
Nbr. of units in pkg.	1
Package weight(Lbs)	0.25
Returnability	N
Country of origin	RO


### Offer Sustainability

Sustainable offer status	Green Premium product
RoHS (date code: YYWW)	Compliant - since 0640 - Schneider Electric declaration of conformity <a href="#">Schneider Electric declaration of conformity</a>
REACH	Reference not containing SVHC above the threshold
Product environmental profile	Available
Product end of life instructions	Need no specific recycling operations

### Contractual warranty

Warranty period	18 months
-----------------	-----------

Sets of Busbars GV2G445, GV2G454, GV2G472, with Terminal Block GV2G05

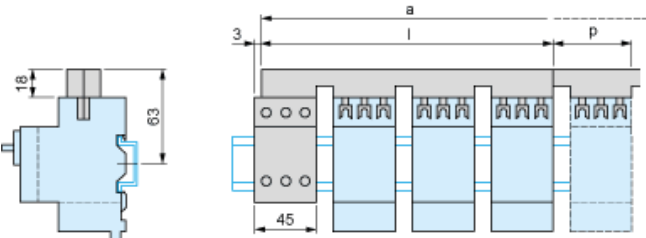

		l	p	
GV2G445 (4 x 45 mm)		179	45	
GV2G454 (4 x 54 mm)		206	54	
GV2G472 (4 x 72 mm)		260	72	

Number of tap-offs	a			
	5	6	7	8
GV2G445	224	269	314	359
GV2G454	260	314	368	422
GV2G472	332	404	476	548

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Schneider Electric:](#)

[GV2G472](#)