

Product availability: Stock - Normally stocked in distribution facility



### Main

Range	Linergy
Product name	FT
Device short name	GV2G
Product or component type	Comb busbar
Accessory / separate part category	Connection accessory
Poles description	3P
Range compatibility	TeSys - GV2 TeSys - U TeSys - D TeSys - K
Number of tap-offs	5
[I <sub>th</sub> ] conventional free air thermal current	63 A
Connection pitch	2.13 in (54 mm)


### Complementary

Mounting location	On terminal
[Ui] rated insulation voltage	690 V
Length	10.24 in (260 mm)
Product weight	0.22 lb(US) (0.1 kg)

### Ordering and shipping details

Category	22367 - MANUAL STR PROTECTOR - GV2
Discount Schedule	I11
GTIN	00785901490128
Nbr. of units in pkg.	1
Package weight(Lbs)	0.2399999999999999
Returnability	Y
Country of origin	RO

### Offer Sustainability

Sustainable offer status	Green Premium product
RoHS (date code: YYWW)	Compliant - since 0640 - Schneider Electric declaration of conformity  Schneider Electric declaration of conformity
REACH	Reference not containing SVHC above the threshold
Product environmental profile	Available
Product end of life instructions	Need no specific recycling operations


### Contractual warranty

Warranty period	18 months
-----------------	-----------

---

## Set of Busbars GV2G554

---

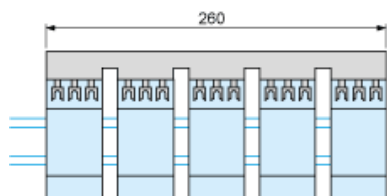

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Schneider Electric:](#)

[GV2G554](#)