

# ZBVG15

white light block for head Ø22 integral LED  
110...120V spring clamp terminals

Product availability: Stock - Normally stocked in distribution facility



## Main

|                               |                            |
|-------------------------------|----------------------------|
| Range of product              | Harmony XB5<br>Harmony XB4 |
| Product or component type     | Light block                |
| Device short name             | ZBV                        |
| Sale per indivisible quantity | 4                          |
| Connections - terminals       | Spring clamp terminals     |
| Signalling type               | Steady                     |
| Light source                  | Protected LED              |
| Bulb base                     | Integral LED               |
| Light block supply            | Direct                     |
| Light source colour           | White                      |
| [Us] rated supply voltage     | 110...120 V AC, 50/60 Hz   |

## Complementary

|                             |                                                                   |
|-----------------------------|-------------------------------------------------------------------|
| Product weight              | 0.04 lb(US) (0.016 kg)                                            |
| Current consumption         | 14 mA                                                             |
| Service life                | 100000 h at rated voltage and 25 °C                               |
| Surge withstand             | 1 kV conforming to IEC 61000-4-5                                  |
| Mounting of block           | Front mounting                                                    |
| Electrical composition code | M1<br>M2<br>M3<br>M4<br>M5<br>M6<br>M10<br>MF1<br>P1<br>P2<br>PF1 |
| Compatibility code          | ZBV                                                               |

## Environment

|                                       |                                                                                                                                    |
|---------------------------------------|------------------------------------------------------------------------------------------------------------------------------------|
| Protective treatment                  | TH                                                                                                                                 |
| Ambient air temperature for storage   | -40...158 °F (-40...70 °C)                                                                                                         |
| Ambient air temperature for operation | -40...158 °F (-40...70 °C)                                                                                                         |
| IP degree of protection               | IP20 conforming to IEC 60529                                                                                                       |
| Standards                             | EN/IEC 60947-5-5<br>EN/IEC 60947-5-4<br>EN/IEC 60947-1<br>JIS C 4520<br>UL 508<br>EN/IEC 60947-5-1<br>CSA C22.2 No 14              |
| Resistance to fast transients         | 2 kV conforming to IEC 61000-4-4                                                                                                   |
| Resistance to electromagnetic fields  | 9.14 V/yd (10 V/m) conforming to IEC 61000-4-3                                                                                     |
| Resistance to electrostatic discharge | 6 kV on contact (on metal parts) conforming to IEC 61000-4-2<br>8 kV in free air (in insulating parts) conforming to IEC 61000-4-2 |
| Electromagnetic emission              | Class B conforming to IEC 55011                                                                                                    |

## Ordering and shipping details

|                       |                                         |
|-----------------------|-----------------------------------------|
| Category              | 22469 - PUSHBUTTON,22MM ACCESSORIES-NEW |
| Discount Schedule     | CS2                                     |
| GTIN                  | 00785901707844                          |
| Nbr. of units in pkg. | 4                                       |
| Package weight(Lbs)   | 0.02                                    |
| Returnability         | Y                                       |
| Country of origin     | FR                                      |

## Offer Sustainability


|                            |                                                                                                                                  |
|----------------------------|----------------------------------------------------------------------------------------------------------------------------------|
| California proposition 65  | WARNING: This product can expose you to chemicals including:                                                                     |
| - - - - - Substance 1      | Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. |
| - - - - - More information | For more information go to <a href="http://www.p65warnings.ca.gov">www.p65warnings.ca.gov</a>                                    |

## Contractual warranty

|                 |           |
|-----------------|-----------|
| Warranty period | 18 months |
|-----------------|-----------|

## Dimensions

with ZB5AZ009 Fixing Collar

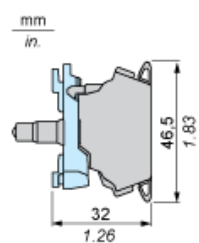

with ZB4BZ009 Fixing Collar



# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Schneider Electric:](#)

[ZBVG15](#)