

Product availability: Non-Stock - Not normally stocked in distribution facility



### Main

|                                    |                                      |
|------------------------------------|--------------------------------------|
| Range of product                   | Harmony XVB Universal                |
| Product or component type          | Indicator bank                       |
| Beacon or indicator bank unit type | Illuminated unit                     |
| Signalling type                    | Flashing                             |
| Mounting diameter                  | 2.76 in (70 mm)                      |
| Component name                     | XVBC                                 |
| Material                           | Polycarbonate                        |
| Light source                       | Orange integral flash discharge tube |
| Bulb type                          | Flash discharge tube                 |
| [Us] rated supply voltage          | 24 V AC/DC                           |
| Flash energy                       | 10 J                                 |

### Complementary

|                                        |                                                                         |
|----------------------------------------|-------------------------------------------------------------------------|
| Assembly style                         | Customer assembly, up to 5 units                                        |
| Connections - terminals                | Screw clamp terminals : $\leq 1 \times 1.5 \text{ mm}^2$ with cable end |
| [Ui] rated insulation voltage          | 250 V conforming to IEC 60947-1                                         |
| Nominal voltage limit                  | 0.85...1.1 Un conforming to IEC 60947-5-1                               |
| Current consumption                    | < 1300 mA AC<br>< 850 mA DC                                             |
| [Uimp] rated impulse withstand voltage | 4 kV conforming to IEC 60947-1                                          |
| Flashing frequency                     | 1 Hz                                                                    |
| CAD overall width                      | 2.76 in (70 mm)                                                         |
| CAD overall height                     | 6.18 in (157 mm)                                                        |
| CAD overall depth                      | 2.76 in (70 mm)                                                         |
| Product weight                         | 0.67 lb(US) (0.305 kg)                                                  |

### Environment

|                                     |                                                                                                  |
|-------------------------------------|--------------------------------------------------------------------------------------------------|
| Product certifications              | GOST<br>UL 508<br>CCC<br>CSA C22-2 No 14                                                         |
| Standards                           | EN/IEC 60947-5-1                                                                                 |
| Protective treatment                | TC                                                                                               |
| Ambient air temperature for storage | -40...158 °F (-40...70 °C)                                                                       |
| Electrical shock protection class   | Class I on support tube conforming to IEC 61140<br>Class II on base unit conforming to IEC 61140 |
| IP degree of protection             | IP65 on fixing base XVBZ0. conforming to IEC 60529<br>IP66 on base unit conforming to IEC 60529  |
| NEMA degree of protection           | NEMA 4X indoor conforming to UL 508                                                              |

### Ordering and shipping details

|                       |                         |
|-----------------------|-------------------------|
| Category              | 22611 - XVB-STACKLIGHTS |
| Discount Schedule     | XV                      |
| GTIN                  | 00785901368847          |
| Nbr. of units in pkg. | 1                       |
| Package weight(Lbs)   | 0.6700000000000004      |

|                   |    |
|-------------------|----|
| Returnability     | N  |
| Country of origin | CZ |

### Offer Sustainability

|                            |                                                                                                                                  |
|----------------------------|----------------------------------------------------------------------------------------------------------------------------------|
| California proposition 65  | WARNING: This product can expose you to chemicals including:                                                                     |
| - - - - - Substance 1      | Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. |
| - - - - - More information | For more information go to <a href="http://www.p65warnings.ca.gov">www.p65warnings.ca.gov</a>                                    |


### Contractual warranty

|                 |           |
|-----------------|-----------|
| Warranty period | 18 months |
|-----------------|-----------|

Indicator Bank with “Flash” Discharge Tube Unit

Dimensions

Below drawing shows the minimum configuration of the product. Select the number of stages according to the product characteristics in order to get b dimension.

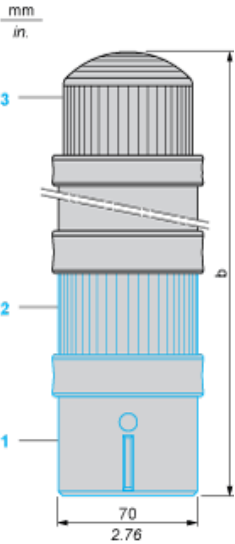

- (1) Base unit XVBC07, to be ordered separately
- (2) Illuminated or audible signalling unit XVBC\*\*\*, to be ordered separately
- (3) “Flash” unit

| Number of illuminated or audible signalling units other than “flash” tube | b in mm | b in in. |
|---------------------------------------------------------------------------|---------|----------|
| 1                                                                         | 295     | 11.61    |
| 2                                                                         | 358     | 14.09    |
| 3                                                                         | 421     | 16.57    |
| 4                                                                         | 484     | 19.06    |

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Schneider Electric:](#)

[XVBC8B5](#)