

XVDLS6M4

Harmony XVDLS, Monolithic tower light, plastic, red, Ø45, flashing, integral flash discharge tube 1 joule, 230 V AC



Main

Range of Product	Harmony XVD Optimum
Product or Component Type	Complete miniature beacon
Beacon or indicator bank unit type	Base unit direct fixing Illuminated unit
Signalling type	Flashing
Mounting diameter	1.77 in (45 mm)
Component name	XVDLS
Material	Glass reinforced polyamide base unit Polycarbonate illuminated unit
Light source	Integral flash discharge tube, red
Bulb type	Flash discharge tube
[Us] rated supply voltage	230 V AC

Complementary

Connections - terminals	Screw clamp terminals, <= 1 x 1.5 mm² with cable end
Cable entry	1 entry tapped Pg 7
[Ui] rated insulation voltage	250 V IEC 60947-1
Current consumption	< 25 mA AC
[Uimp] rated impulse withstand voltage	4 kV IEC 60947-1
Flash energy	1 J
CAD overall width	1.77 in (45 mm)
CAD overall height	4.09 in (104 mm)
CAD overall depth	1.77 in (45 mm)
Terminals description ISO n°1	(COM-1)PW (GND)GROUND
Net Weight	0.19 lb(US) (0.085 kg)

Environment

Product Certifications	UL CSA
Standards	EN/IEC 60947-5-1
Protective treatment	TC
Ambient Air Temperature for Storage	-40...158 °F (-40...70 °C)
Electrical shock protection class	Class II IEC 60536
IP degree of protection	IP40 IEC 60529

Ordering and shipping details

Category	22611 - XVB-STACKLIGHTS
Discount Schedule	XV
GTIN	3389110111002
Nbr. of units in pkg.	1
Package weight(Lbs)	3.53 oz (100 g)
Returnability	No
Country of origin	CZ

Packing Units

Unit Type of Package 1	PCE
Package 1 Height	2.20 in (5.6 cm)
Package 1 width	2.20 in (5.6 cm)
Package 1 Length	4.41 in (11.2 cm)
Unit Type of Package 2	S01
Number of Units in Package 2	12
Package 2 Weight	3.10 lb(US) (1.407 kg)
Package 2 Height	5.91 in (15 cm)
Package 2 width	5.91 in (15 cm)
Package 2 Length	15.75 in (40 cm)

Offer Sustainability


Sustainable offer status	Green Premium product
California proposition 65	WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov
REACH Regulation	REACH Declaration
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS Declaration
Environmental Disclosure	Product Environmental Profile
WEEE	The product must be disposed on European Union markets following specific waste collection and never end up in rubbish bins.

Contractual warranty

Warranty	18 months
----------	-----------


Illuminated Beacon

Dimensions

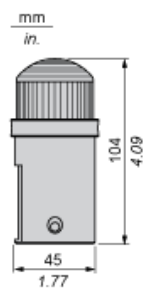

Illuminated Beacon

Panel Cut-out for Direct Fixing

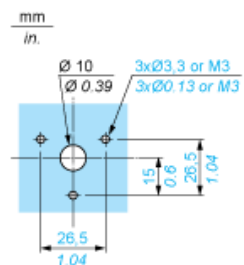

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Schneider Electric:](#)

[XVDLS6M4](#)