

XVEC5G5

ORANGE LENS INTEGRAL FLASHING LED

120VAC



Main

Range of Product	Harmony XVE Optimum
Product or Component Type	Indicator bank
Beacon or indicator bank unit type	Illuminated unit
Signalling type	Flashing
Component name	XVE
Light source	Integral LED, orange
Bulb type	LED
[Us] rated supply voltage	120 V AC

Complementary

Mounting diameter	2.76 in (70 mm)
Assembly style	Customer assembly
Connections - terminals	Screw clamp terminals, <= 1 x 1.5 mm² with cable end
Marking	CE
Short-circuit protection	0.16 A
[Ui] rated insulation voltage	250 V IEC 60947-1
Nominal voltage limit	0.85...1.1 Un IEC 60947-5-1
Current consumption	< 25 mA
[Uimp] rated impulse withstand voltage	4 kV IEC 60947-1
Luminance	74.32 fc (800 cd/m²)
Flashing frequency	1 Hz
CAD overall width	2.76 in (70 mm)
CAD overall height	2.05 in (52 mm)
CAD overall depth	2.76 in (70 mm)
Net Weight	0.17 lb(US) (0.077 kg)

Environment

Standards	EN/IEC 60947-1 EN/IEC 60947-5-1
Product Certifications	CCC UL CSA
Ambient Air Temperature for Storage	-40...158 °F (-40...70 °C)
Ambient air temperature for operation	-13...131 °F (-25...55 °C)
Electrical shock protection class	Class I aluminium tube mounting IEC 61140 Class I plastic tube mounting IEC 61140
Protective treatment	TC
IP degree of protection	IP40 any position except vertical position IEC 60529 IP42 vertical position IEC 60529

Ordering and shipping details

Category	22616 - XVE OPTIMUM STACKLIGHTS
Discount Schedule	XV
GTIN	00785901661917
Nbr. of units in pkg.	1
Package weight(Lbs)	0.17 lb(US) (0.08 kg)
Returnability	No
Country of origin	CZ

Packing Units

Package 1 Height	0.700 dm
Package 1 width	1.600 dm
Package 1 Length	2.300 dm


Contractual warranty

Warranty	18 months
----------	-----------

Indicator Bank

Dimensions

Below drawing shows the minimum configuration of the product. Select the number of stages according to the product characteristics in order to get b dimension.

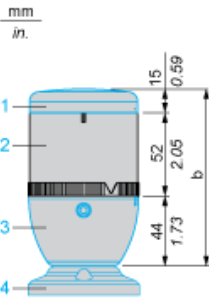

- (1) Cover (supplied with base unit XVEC21/C21P)
- (2) Illuminated or audible unit
- (3) Base unit XVEC21/C21P, to be ordered separately
- (4) Fixing base, to be ordered separately

Number of units (ref. 2)	b in mm	b in in.
1 unit	111	4.37
2 units	163	6.42
3 units	215	8.46
4 units	267	10.51
5 units	319	12.56

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Schneider Electric:](#)

[XVEC5G5](#)