

Product availability: Non-Stock - Not normally stocked in distribution facility



### Main

|                           |                                                 |
|---------------------------|-------------------------------------------------|
| Range of product          | Harmony XVS                                     |
| Product or component type | Siren                                           |
| Device short name         | XVS                                             |
| Color                     | White                                           |
| Signalling type           | 2 tones siren                                   |
| [Us] rated supply voltage | 230 V AC                                        |
| Noise level               | 106 dB (continuous or intermittent tone) at 1 m |

### Complementary

|                                        |                                      |
|----------------------------------------|--------------------------------------|
| Material                               | PC (body)                            |
| Product weight                         | 2.2 lb(US) (1 kg)                    |
| Marking                                | CE                                   |
| [Uimp] rated impulse withstand voltage | 4 kV                                 |
| Current consumption                    | 40 mA at 230 V                       |
| Clamping connection capacity           | <= 1 x 1.5 mm <sup>2</sup>           |
| Electrical connection                  | Cable: 0.26...0.33 in (6.5...8.5 mm) |
| Width                                  | 4.49 in (114 mm)                     |
| Height                                 | 4.49 in (114 mm)                     |
| Depth                                  | 6.03 in (153.2 mm)                   |

### Environment

|                                       |                                     |
|---------------------------------------|-------------------------------------|
| Standards                             | EN/IEC 60947-5-1<br>EN/IEC 60947-1  |
| Protective treatment                  | TC                                  |
| Ambient air temperature for storage   | -31...158 °F (-35...70 °C)          |
| Ambient air temperature for operation | -22...122 °F (-30...50 °C)          |
| Electrical shock protection class     | Class II conforming to EN/IEC 61140 |
| IP degree of protection               | IP53 conforming to EN/IEC 60529     |

### Ordering and shipping details

|                       |                          |
|-----------------------|--------------------------|
| Category              | 22617 - XVC TOWER LIGHTS |
| Discount Schedule     | XV                       |
| GTIN                  | 00785901944782           |
| Nbr. of units in pkg. | 1                        |
| Package weight(Lbs)   | 2.7000000000000002       |
| Returnability         | N                        |
| Country of origin     | ID                       |

## Offer Sustainability


|                                  |                                                                                                                                                                                                        |
|----------------------------------|--------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| Sustainable offer status         | Green Premium product                                                                                                                                                                                  |
| RoHS (date code: YYWW)           | Compliant - since 1611 - Schneider Electric declaration of conformity  Schneider Electric declaration of conformity |
| REACH                            | Reference not containing SVHC above the threshold                                                                                                                                                      |
| Product environmental profile    | Available                                                                                                                                                                                              |
| Product end of life instructions | Available                                                                                                                                                                                              |
| California proposition 65        | WARNING: This product can expose you to chemicals including:                                                                                                                                           |
| - - - - - Substance 1            | Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm.                                                                       |
| - - - - - More information       | For more information go to <a href="http://www.p65warnings.ca.gov">www.p65warnings.ca.gov</a>                                                                                                          |

## Contractual warranty

|                 |           |
|-----------------|-----------|
| Warranty period | 18 months |
|-----------------|-----------|

Siren

Dimensions

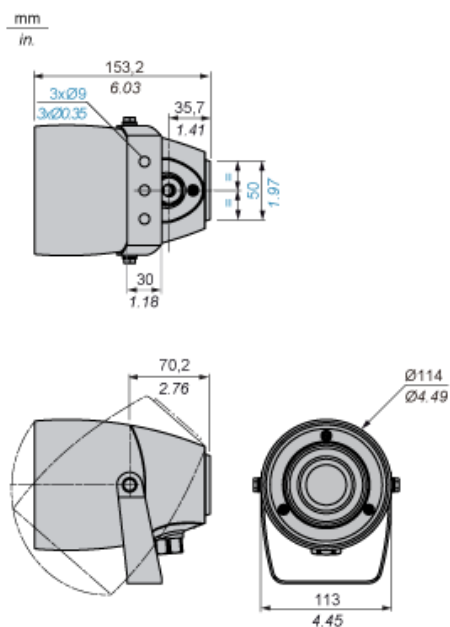

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Schneider Electric:](#)

[XVS10MMW](#)