

XVS14GMW

Multisound siren, Harmony XVS, Multi sound white, 0...105 dB, 43 tones, 8 channels, 120 V AC



Main

Range of product	Harmony XVS
Product or Component Type	Multisound siren
Device short name	XVS

Complementary

Color	White
Material	PC (polycarbonate) back cover PC (polycarbonate)/ABS (acrylonitrile butadiene-styrene) front PC (polycarbonate)/ABS (acrylonitrile butadiene-styrene) back
Product Weight	2.65 lb(US) (1.2 kg)
Marking	CE
Mounting Support	Bracket
Fixing Mode	3 holes Ø 9 mm
[Uimp] rated impulse withstand voltage	4 kV
Current consumption	100 mA 120 V
Electrical connection	Cable 0.26...0.33 in (6.5...8.5 mm), 0.00 in² (0.33 mm²) / AWG 22 signalling circuit) Cable 0.26...0.33 in (6.5...8.5 mm), 0.00 in² (0.52 mm²) / AWG 20 power circuit)
Width	5.51 in (140 mm)
Height	4.49 in (114 mm)
Depth	8.78 in (223 mm)

Environment

Signalling type	43 tones siren
Standards	EN 61000-6-2 EN 61000-6-3 EN 60947 EN 60947-5
Product Certifications	UL
Protective treatment	TC
Ambient Air Temperature for Storage	-31...158 °F (-35...70 °C)
Ambient Air Temperature for Operation	14...122 °F (-10...50 °C)
Overvoltage category	Class II EN/IEC 61140
IP degree of protection	IP53 conforming to EN/IEC 60529
[Us] rated supply voltage	120 V AC
Noise level	0...105 dB continuous or intermittent tone)1 m

Ordering and shipping details

Category	22617 - XVC TOWER LIGHTS
Discount Schedule	XV
GTIN	3606480072048
Nbr. of units in pkg.	1
Package weight(Lbs)	3.50 lb(US) (1.586 kg)
Returnability	No
Country of origin	ID

Packing Units

Unit Type of Package 1	PCE
Package 1 Height	11.02 in (28 cm)
Package 1 width	6.10 in (15.5 cm)
Package 1 Length	6.10 in (15.5 cm)
Unit Type of Package 2	S04
Number of Units in Package 2	6
Package 2 Weight	23.74 lb(US) (10.768 kg)
Package 2 Height	11.81 in (30 cm)
Package 2 width	15.75 in (40 cm)
Package 2 Length	23.62 in (60 cm)

Offer Sustainability

California proposition 65	WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS Declaration
Environmental Disclosure	Product Environmental Profile
Circularity Profile	End Of Life Information


Contractual warranty

Warranty	18 months
----------	-----------

Siren

Dimensions

mm
in.

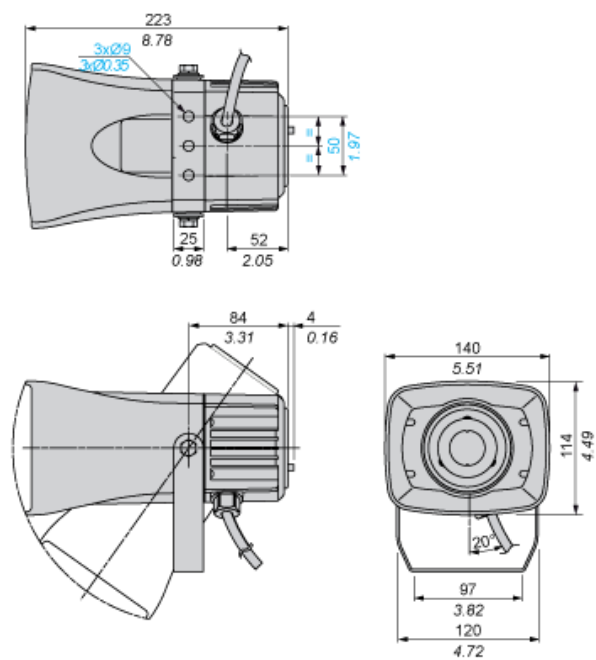

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Schneider Electric:](#)

[XVS14GMW](#)