


Product availability: Stock - Normally stocked in distribution facility

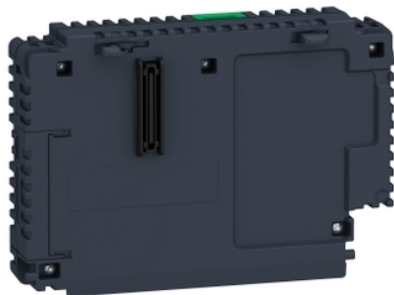

### Main

Range of product	Magelis GTU
Product or component type	Base unit
Device short name	Premium Box
Processor name	CPU RISC 600 MHz
Operating system	Magelis
Software package	Vijeo Designer run time

### Complementary

Range compatibility	Magelis GTU
Data storage equipment	1 GB SD card
Port Ethernet	10BASE-T/100BASE-TX/1000BASE-T
Memory description	Backup memory 512 kB NVRAM Internal 256 MB RAM 2 x 13 mm board
Type of cooling	Natural convection
Integrated connection type	USB 2.0 port mini B USB Auxiliary port terminal block Expansion unit fieldbus card Ethernet TCP/IP with 2 RJ45 COM1 serial link RJ45 RS485, transmission rate: 110...115200 bit/s COM1 serial link RJ45 RS485, transmission rate: 187.5 kbit/s COM2 serial link SUB-D 9 RS232C/RS422/RS485, transmission rate: 110...115200 bit/s COM2 serial link SUB-D 9 RS232C/RS422/RS485, transmission rate: 187.5 kbit/s USB 2.0 port with 2 USB type A
Communication port protocol	Modbus TCP/IP Modbus Uni-Telway
[Us] rated supply voltage	12...24 V DC power supply
Depth	1.77 in (45 mm)
Height	5.16 in (131 mm)
Width	7.4 in (188 mm)
Product weight	1.98 lb(US) (0.9 kg)
Number of slots available for expansion	2 SD card

The information provided in this documentation contains general descriptions and/or technical characteristics of the products of the products contained herein. This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications. It is the duty of any such user or integrator to perform the appropriate and complete risk analysis, evaluation and testing of the products with respect to the relevant specific application or use thereof. Neither Schneider Electric Industries SAS nor any of its affiliates or subsidiaries shall be responsible or liable for misuse of the information contained herein.

## Environment

Standards	CSA C22.2 No 142 ANSI/ISA 12-12-01 CSA C22.2 No 213 class I division 2 IEC 61132-2 UL 508
Product certifications	CCS EAC KC ATEX RCM CUL IEC-Ex GL ABS BV DNV LR RINA CULus CE
Pollution degree	2 conforming to EN 61131-2 Ed.3
Electromagnetic compatibility	Electrostatic discharge immunity test EN/IEC 61000-4-2 level 3
Ambient air temperature for storage	-4...140 °F (-20...60 °C)
Relative humidity	10...90 % non-condensing
Ambient air temperature for operation	32...140 °F (0...60 °C)
Operating altitude	6561.68 ft (2000 m)
Vibration resistance	3.5 mm constant amplitude 5...9 Hz conforming to EN/IEC 61131-2 9.8 m/s² 9...150 Hz conforming to EN/IEC 61131-2

## Ordering and shipping details

Category	22567 - MAGELIS HMI GTU
Discount Schedule	MC2
GTIN	00785901116318
Nbr. of units in pkg.	1
Package weight(Lbs)	2.7600000000000002
Returnability	Y
Country of origin	CN

## Offer Sustainability


Sustainable offer status	Green Premium product
RoHS (date code: YYWW)	Compliant - since 1347 - Schneider Electric declaration of conformity <a href="#">Schneider Electric declaration of conformity</a>
REACH	Reference not containing SVHC above the threshold
Product environmental profile	Available <a href="#">Product Environmental Profile</a>
Product end of life instructions	Available <a href="#">End Of Life Information</a>
California proposition 65	WARNING: This product can expose you to chemicals including:
- - - - - Substance 1	Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm.
- - - - - More information	For more information go to <a href="http://www.p65warnings.ca.gov">www.p65warnings.ca.gov</a>

## Contractual warranty

Warranty period	18 months
-----------------	-----------

## Dimensions

### External Dimensions

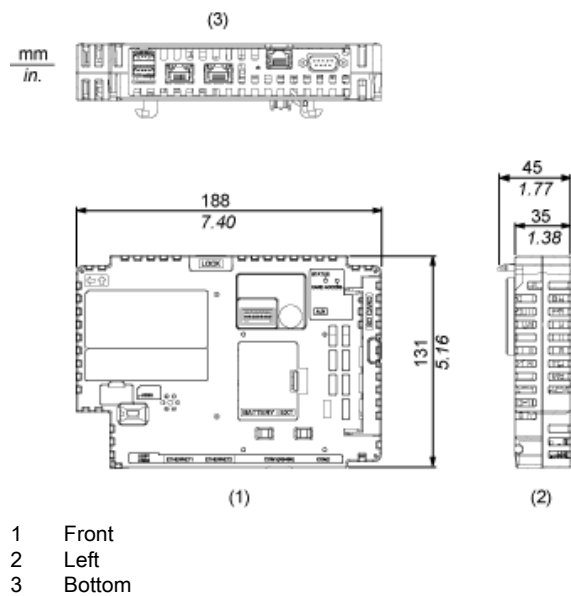

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Schneider Electric:](#)

[HMIG3U](#)