



Main

Range	Linergy
Product name	FT
Device short name	GV2G
Product or component type	Comb busbar
Accessory / separate part category	Connection accessory
Poles description	3P
Range compatibility	TeSys - GV2 TeSys - U TeSys - D TeSys - K
Number of tap-offs	3
[Ith] conventional free air thermal current	63 A
Connection pitch	2.13 in (54 mm)

Complementary

Mounting location	On terminal
[Ui] rated insulation voltage	690 V
Length	6.38 in (162 mm)
Product weight	0.13 lb(US) (0.06 kg)

Environment


Offer Sustainability

Green Premium product	Green Premium product
Compliant - since 0640 - Schneider Electric declaration of conformity	Compliant - since 0640 - Schneider Electric declaration of conformity
Reference not containing SVHC above the threshold	Reference not containing SVHC above the threshold
Available	Available
Need no specific recycling operations	Need no specific recycling operations

Contractual warranty

Warranty period	18 months
-----------------	-----------

Sets of Busbars GV2G345 and GV2G354

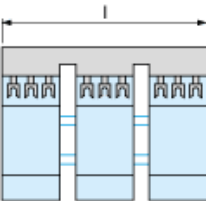

	I
GV2G345 (3 x 45 mm)	134
GV2G354 (3 x 54 mm)	152

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Schneider Electric:](#)

[GV2G354](#)